


[メトリック]スプリングロールピン
EA949PC-151~609



●材質…鉄

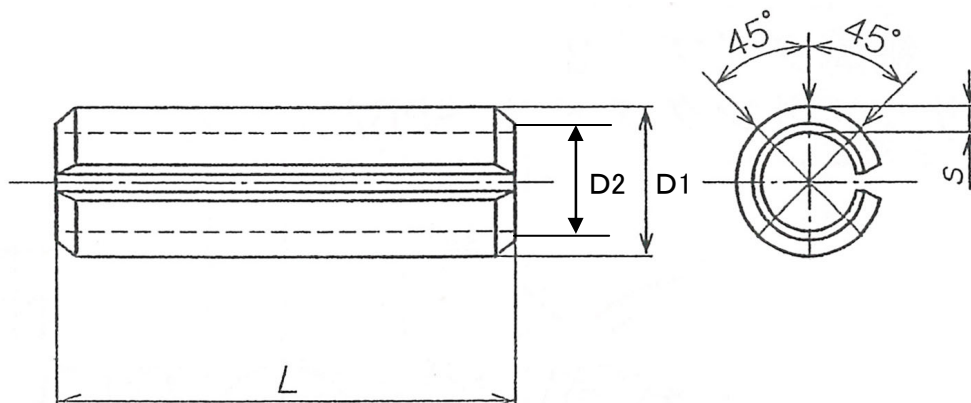

品番	呼び径	サイズ(mm)				適用穴径 (mm)	二重せん断荷重		入数 (本)	重量(g) (1本)
		L	D1	D2	S		kgf	kN		
EA949PC-151	1.5	5	1.60	1.40	0.30	1.50	158	1.55	47	0.05
EA949PC-152		10							42	0.08
EA949PC-153		12							31	0.11
EA949PC-154		15							29	0.14
EA949PC-155		18							25	0.16
EA949PC-201	2	5	2.15	1.90	0.40	2.00	281	2.76	42	0.08
EA949PC-202		10							38	0.16
EA949PC-203		12							29	0.19
EA949PC-204		15							24	0.23
EA949PC-205		18							21	0.28
EA949PC-206		20							18	0.31
EA949PC-207		25							16	0.39
EA949PC-251	2.5	5	2.65	2.40	0.50	2.50	440	4.30	27	0.12
EA949PC-252		10							25	0.24
EA949PC-253		12								0.29
EA949PC-254		15							22	0.36
EA949PC-255		18							18	0.43
EA949PC-256		20							16	0.48
EA949PC-257		25							14	0.60

品番	呼び径	サイズ(mm)				適用穴径 (mm)	二重せん断荷重		入数 (本)	重量(g) (1本)
		L	D1	D2	S		kgf	kN		
EA949PC-301	3	10	3.15	2.90	0.60	3.00	633	6.20	18	0.38
EA949PC-302		12								0.46
EA949PC-303		15								0.57
EA949PC-304		18								0.68
EA949PC-305		20								0.76
EA949PC-306		25								0.94
EA949PC-307		30								1.13
EA949PC-308		35								1.32
EA949PC-309		40								1.51
EA949PC-351	3.5	10	3.70	3.40	0.70	3.50	861	8.44	18	0.49
EA949PC-352		12								0.58
EA949PC-353		15								0.73
EA949PC-354		18								0.87
EA949PC-355		20								0.97
EA949PC-356		25								1.21
EA949PC-357		30								1.45
EA949PC-358		35								1.69
EA949PC-401	4	10	4.20	3.90	0.80	4.00	1130	11.08	14	0.62
EA949PC-402		12								0.74
EA949PC-403		15								0.92
EA949PC-404		18								1.11
EA949PC-405		20								1.23
EA949PC-406		25								1.53
EA949PC-407		30								1.84
EA949PC-408		35								2.15
EA949PC-409		40								2.45
EA949PC-501	5	10	5.20	4.80	1.00	5.00	1760	17.25	11	0.92
EA949PC-502		12								1.10
EA949PC-503		16								1.51
EA949PC-504		18								1.69
EA949PC-505		20								1.88
EA949PC-506		25								2.29
EA949PC-507		30								2.81
EA949PC-601	6	10	6.20	5.80	1.20	6.00	2532	24.83	8	1.39
EA949PC-602		12								1.67
EA949PC-603		16								2.22
EA949PC-604		18								2.50
EA949PC-605		20								2.78
EA949PC-606		25								3.33
EA949PC-607		30								4.16
EA949PC-608		35								4.85
EA949PC-609		40								5.55