


EA949PH-16

[ステンレス製]スナップピン
EA949PH-4~16

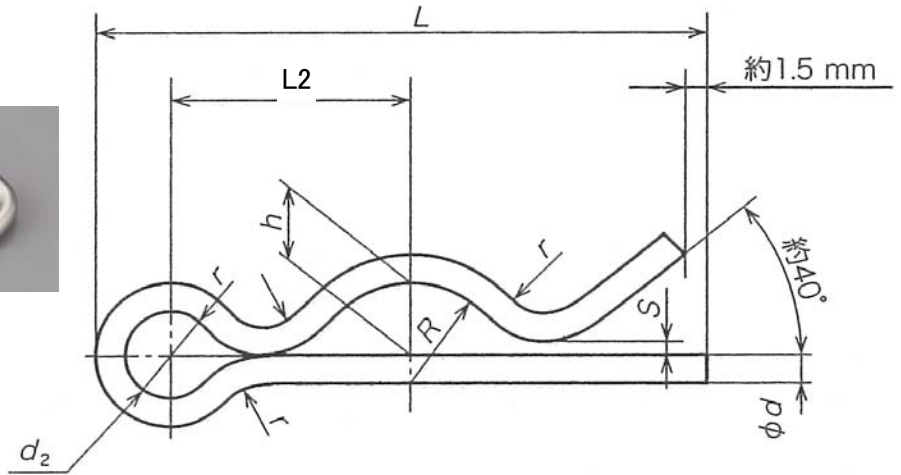

●材質…ステンレス (SUS304)

品番	呼び	サイズ(mm)								入数	重量(g) (1個)
		d	d2	L2	R	h	S	L	r		
EA949PH-4	M4	1.00	3.00	6.00	2.00	1.00	0.50	16.30	1.50	35	0.200
EA949PH-5	M5	1.00	3.00	6.50	2.50	1.50	0.50	17.90	1.50	34	0.240
EA949PH-6	M6	1.20	3.60	7.80	3.00	1.80	0.60	21.20	1.80	23	0.400
EA949PH-7	M7	1.20	3.60	8.30	3.50	2.30	0.60	22.80	1.80	22	0.930
EA949PH-8	M8	1.60	4.80	10.40	4.00	2.40	0.80	27.70	2.40	12	0.930
EA949PH-9	M9	1.60	4.80	10.90	4.50	2.90	0.80	29.30	2.40	11	0.990
EA949PH-10	M10	1.80	5.40	12.20	5.00	3.20	0.90	32.60	2.70	9	1.400
EA949PH-12	M12	1.80	5.40	13.20	6.00	4.20	0.90	35.80	2.70	7	1.600
EA949PH-14	M14	2.00	6.00	15.00	7.00	5.00	1.00	40.06	3.00	5	2.139
EA949PH-16	M16	2.00	6.00	16.00	8.00	6.00	1.00	43.80	3.00		2.326