


## ダイヤピン

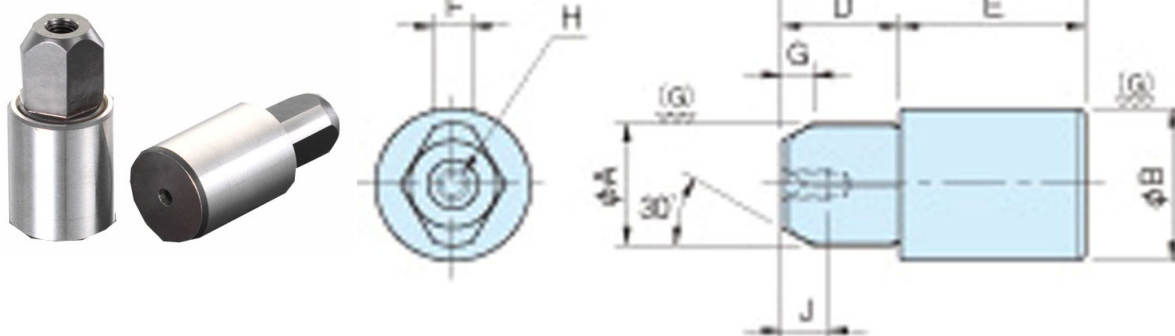

| 品番         | サイズ(mm) |       |    |    |    |     |   |        |     | 重量(g) |
|------------|---------|-------|----|----|----|-----|---|--------|-----|-------|
|            | A(h6)   | B(p6) | C  | D  | E  | F   | G | H      | J   |       |
| EA949RK-21 | 6       | 10    | 20 | 9  | 11 | 1.8 | 2 | M3X0.5 | 4.5 | 7     |
| EA949RK-22 | 8       | 12    | 25 | 11 | 14 | 2.2 | 3 |        |     | 15    |
| EA949RK-23 | 10      | 14    | 30 | 13 | 17 | 3.3 | 3 |        |     | 26    |
| EA949RK-24 | 12      | 16    | 34 | 14 | 20 | 3.5 | 4 | M5X0.8 | 8   | 40    |
| EA949RK-25 | 14      | 18    | 38 | 15 | 23 | 4   | 4 |        |     | 60    |
| EA949RK-26 | 16      | 20    | 42 | 16 | 26 | 5   | 4 |        |     | 85    |
| EA949RK-27 | 18      | 22    | 46 | 17 | 29 | 5.5 | 5 |        |     | 115   |
| EA949RK-28 | 20      | 25    | 47 | 17 | 30 | 6   | 5 |        |     | 150   |
| EA949RK-29 | 22      | 28    | 49 | 19 | 30 | 7   | 5 |        |     | 195   |
| EA949RK-30 | 25      | 30    | 49 | 19 | 30 | 8   | 5 |        |     | 235   |

( )内はJIS B 0401-1での穴の公差域クラス

### ●材質

本体:SK95、焼入焼戻、研磨仕上、HRC55～60

RoHS指令適合品