




穴数=4

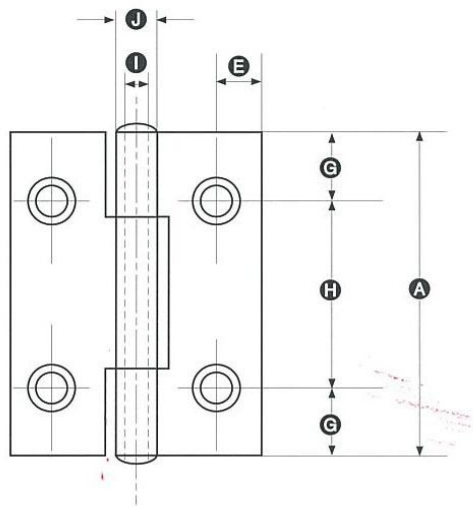



ネジ穴

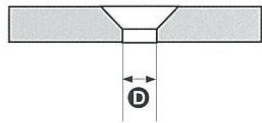

穴数=6

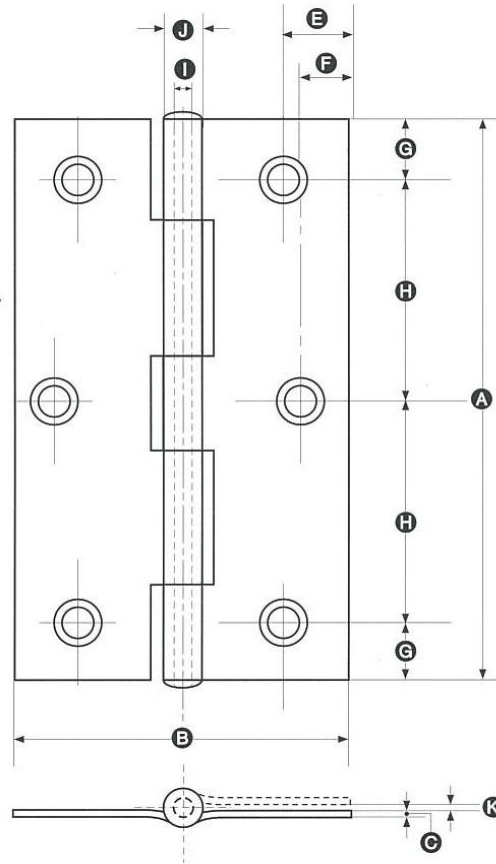

穴数=8

 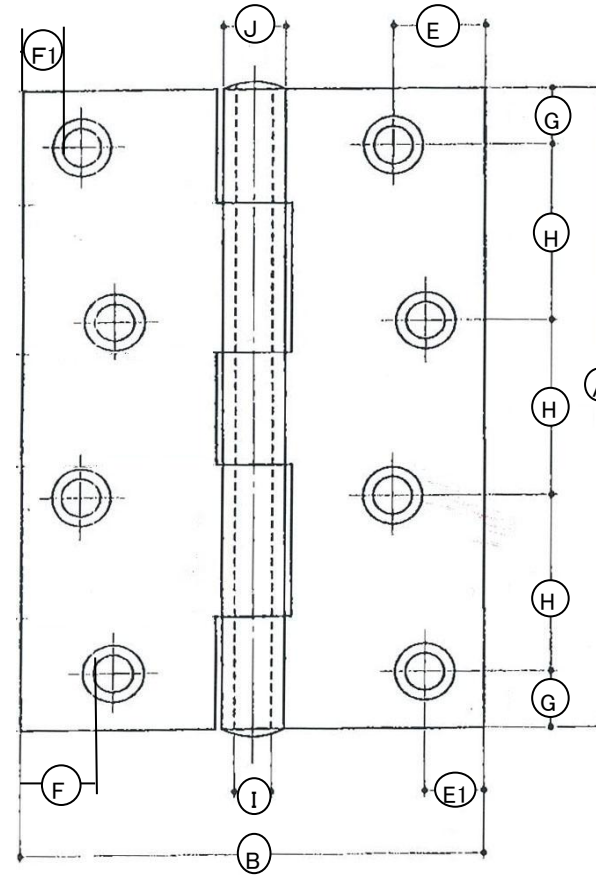

品番	サイズ mm													穴数	入数
	A	B	C	D	E	E1	F	F1	G	H	I	J	K		
EA951CJ-1	51	38	1.3	3.9	7.0	-	-	-	7.5	36	3.4	6.1	1.3	4	2枚
EA951CJ-2	64	42	1.4	4.6	8.0	-	5.7	-	7.0	25	3.4	6.4	1.4	6	
EA951CJ-3	76	49	1.5	5.0	9.0	-	6.5	-	9.0	29	4.2	7.4	1.5	6	
EA951CJ-4	89	56	1.7	5.3	10.5	-	7.85	-	10.5	34	5.2	8.8	1.7	6	
EA951CJ-5	102	70	1.8	5.9	14.0	8.55	11.05	5.6	9.0	28	5.6	9.4	1.8	8	
EA951CJ-51	51	38	1.3	3.9	7.0	-	-	-	7.5	36	3.4	6.1	1.3	4	10枚
EA951CJ-64	64	42	1.4	4.6	8.0	-	5.7	-	7.0	25	3.4	6.4	1.4	6	
EA951CJ-76	76	49	1.5	5.0	9.0	-	6.5	-	9.0	29	4.2	7.4	1.5	6	
EA951CJ-89	89	56	1.7	5.3	10.5	-	7.85	-	10.5	34	5.2	8.8	1.7	6	
EA951CJ-102	102	70	1.8	5.9	14.0	8.55	11.05	5.6	9.0	28	5.6	9.4	1.8	8	