

FTH

フラットヒンジ

標準 **在庫品** **RHS** **SUS**






FTH-H
(サラボルト用)



FTH-HC-SUS
(サラボルト用)



FTH-TC
(オネジ)

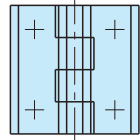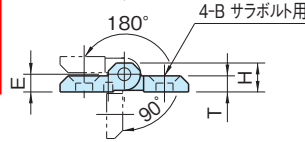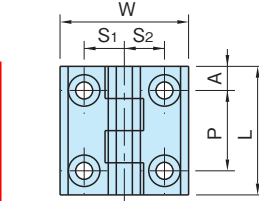

FTH-H **FTH-HC** **FTH-HC-SUS**
(サラボルト用)

FTH-T **FTH-TC**
(オネジ)

タイプ	本体	ピン	オネジ
FTH-H	亜鉛ダイカスト (ZDC1)	SUS303	—
FTH-T	黒色塗装		SUS304
FTH-HC	亜鉛ダイカスト (ZDC1)		—
FTH-TC	クロムメッキ		SUS304
FTH-HC-SUS	SUS316	—	—

★One Point
腐食に強いステンレス製もご用意

サイズ	W	L	S ₁	S ₂	P	H	T	E	A	
FTH-H	3030	30	30	9	9	18	7.5	4	4.3	6
FTH-T	4040	40	40	12.5	12.5	25	9	5	5.5	7.5
FTH-HC	5050	50	50	15	15	30	11.5	6	6.5	10
FTH-TC	6060	60	60	18	18	36	15	8	8.5	12
FTH-HC-SUS	6350	63	50	15	28	30	11.5	6	6.5	10
	7650	76	50	28	30	11.5	6	6.5	6.5	10
	9060	90	60	18	45	36	15	8	8.5	12

EA951CR-61
EA951CR-62
EA951CR-63
EA951CR-64

FTH-H **FTH-HC** **FTH-HC-SUS** (サラボルト用)

亜鉛ダイカスト製

品番	品番	質量 (g)
FTH3030H	—	19
FTH4040H	FTH4040HC	50
FTH5050H	FTH5050HC	95
FTH6060H	FTH6060HC	170
FTH6350H	—	105
FTH7650H	FTH7650HC	125

SUS製

品番	質量 (g)	B
—	—	M4
FTH4040HC-SUS EA951CR-61	50	M5
FTH5050HC-SUS EA951CR-62	104	M6
FTH6060HC-SUS EA951CR-63	214	M8
FTH6350HC-SUS	125	M6
FTH7650HC-SUS EA951CR-64	150	

FTH-T **FTH-TC** (オネジ)

品番	品番	M	L ₁	θ	質量 (g)
FTH4040T	FTH4040TC	M5×0.8	12	約60°	65
FTH5050T	FTH5050TC	M6×1	12	約70°	110
FTH6060T	FTH6060TC	M8×1.25	14		200
FTH7650T	FTH7650TC	M6×1	12	90°	140
FTH9060T	FTH9060TC	M8×1.25	14		270