

HINGES


Metal Leaf Hinges CONTINUED

SR 5506



Die-Cast Zinc Alloy

- Stainless steel pin
- For flush mounted doors
- Maximum rotation 270°



EA951CY-750C

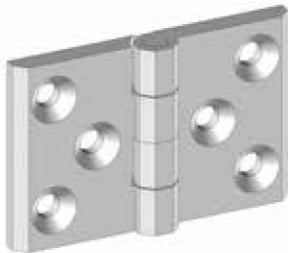


Type 5

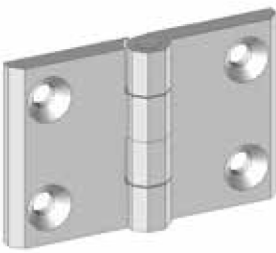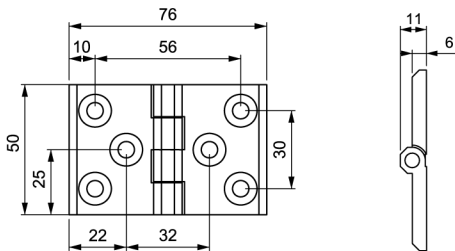


Type 6

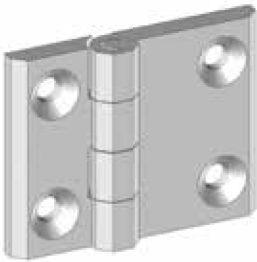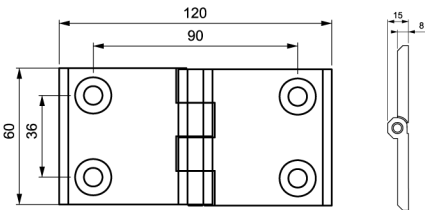

Type 7

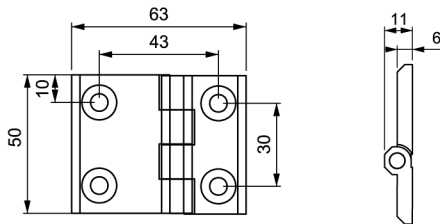

Type 8

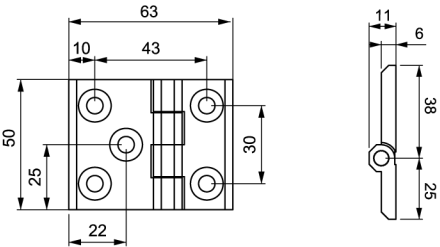

Part Number		Type	Bolt Hole Size	Size (mm)
Chrome Plated	Black Powder Coated			
099116E	099126E	5	M6	76 x 50
399116E	399126E	6	M8	120 x 60
099117E	099127E	7	M6	63 x 50
099115E	099125E	8	M6	63 x 50

EA951CY-750C

All dimensions in mm