




# スタンダードセットカラー ノーマル



| 材質記号     | 材質 / 表面処理    | 付属品                     |
|----------|--------------|-------------------------|
| <b>C</b> | 鉄 S45C / 黒染め | 六角穴付止めネジ(くぼみ先 黒染め)2本    |
| <b>S</b> | ステンレス SUS304 | 六角穴付止めネジ(くぼみ先 SUSXM7)2本 |

材質記号  
**SC 0305** **C**  
内径3mm、幅5mm、黒染め

寸法図

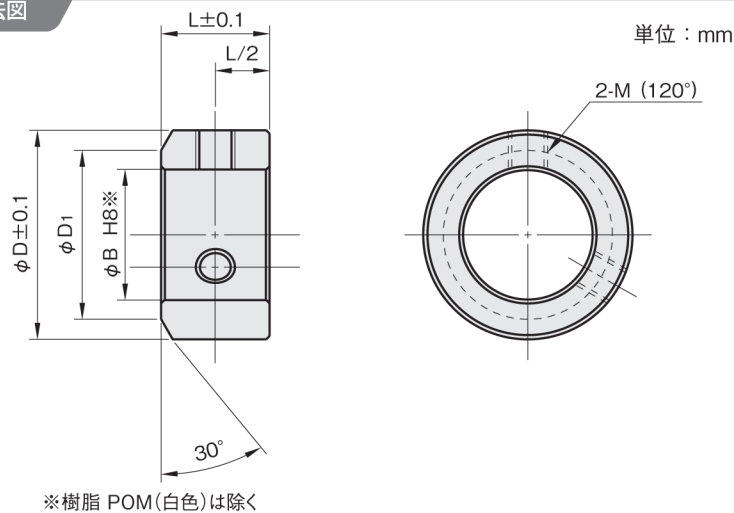

※樹脂 POM(白色)は除く

| 内径<br>φB | 幅<br>L | 外径<br>φD | 面取径<br>φD1 | 締付ネジ<br>M | 品番<br>□:材質記号     | EA品番            |                    |
|----------|--------|----------|------------|-----------|------------------|-----------------|--------------------|
|          |        |          |            |           |                  | 黒染め<br><b>C</b> | SUS304<br><b>S</b> |
| 4        | 6      | 12       | —          | ★M4×4     | <b>SC 0406</b> □ | EA966C-1        | EA966CA-31         |
|          | 8      | 12       | —          | ★M4×4     | <b>SC 0408</b> □ | EA966C-2        | EA966CA-32         |
| 5        | 6      | 14       | —          | ★M4×4     | <b>SC 0506</b> □ | —               | EA966CA-33         |
|          | 8      | 14       | —          | ★M4×4     | <b>SC 0508</b> □ | EA966C-4        | EA966CA-34         |
| 6        | 6      | 15       | —          | ★M4×4     | <b>SC 0606</b> □ | EA966C-5        | —                  |
|          | 8      | 15       | —          | ★M4×4     | <b>SC 0608</b> □ | EA966C-6        | EA966CA-35         |
|          | 10     | 16       | —          | ★M4×4     | <b>SC 0610</b> □ | EA966C-7        | EA966CA-36         |
| 8        | 8      | 16       | 13         | M4×4      | <b>SC 0808</b> □ | EA966C-8        | EA966CA-37         |
|          | 10     | 18       | 13         | M4×4      | <b>SC 0810</b> □ | EA966C-9        | EA966CA-38         |
| 10       | 8      | 18       | 16         | M4×4      | <b>SC 1008</b> □ | EA966C-10       | EA966CA-39         |
|          | 10     | 20       | 16         | M4×4      | <b>SC 1010</b> □ | EA966C-11       | EA966CA-40         |
| 12       | 8      | 22       | 20         | M4×4      | <b>SC 1208</b> □ | EA966C-12       | EA966CA-41         |
|          | 10     | 26       | 20         | M5×6      | <b>SC 1210</b> □ | EA966C-13       | EA966CA-42         |
| 13       | 8      | 22       | 20         | M4×4      | <b>SC 1308</b> □ | EA966C-14       | —                  |
|          | 10     | 26       | 20         | M5×6      | <b>SC 1310</b> □ | EA966C-15       | EA966CA-43         |
| 14       | 12     | 26       | 20         | M5×6      | <b>SC 1412</b> □ | EA966C-16       | —                  |
| 15       | 10     | 25       | 24         | M5×6      | <b>SC 1510</b> □ | EA966C-17       | EA966CA-44         |
|          | 12     | 28       | 24         | M5×6      | <b>SC 1512</b> □ | EA966C-18       | EA966CA-45         |
| 16       | 10     | 28       | 24         | M5×6      | <b>SC 1610</b> □ | EA966C-19       | EA966CA-46         |
|          | 12     | 28       | 24         | M5×6      | <b>SC 1612</b> □ | EA966C-20       | EA966CA-47         |
| 17       | 10     | 30       | 26         | M6×6      | <b>SC 1710</b> □ | EA966C-21       | EA966CA-48         |
|          | 12     | 32       | 26         | M6×6      | <b>SC 1712</b> □ | EA966C-22       | —                  |
| 18       | 15     | 32       | 29         | M6×6      | <b>SC 1815</b> □ | EA966C-23       | —                  |

| 内径<br>φB | 幅<br>L | 外径<br>φD | 面取径<br>φD1 | 締付ネジ<br>M | 品番<br>□:材質記号 | EA品番      |             |
|----------|--------|----------|------------|-----------|--------------|-----------|-------------|
|          |        |          |            |           |              | 黒染め<br>C  | SUS304<br>S |
| 20       | 12     | 32       | 29         | M6×6      | SC 2012□     | EA966C-24 | EA966CA-49  |
|          | 15     | 32       | 29         | M6×6      | SC 2015□     | EA966C-25 | EA966CA-50  |
| 22       | 18     | 38       | 34         | M8×8      | SC 2218□     | EA966C-26 | —           |
| 25       | 15     | 38       | 37         | M6×6      | SC 2515□     | EA966C-27 | EA966CA-51  |
|          | 18     | 42       | 38         | M8×8      | SC 2518□     | —         | —           |
| 28       | 18     | 45       | 40         | M8×8      | SC 2818□     | EA966C-29 | EA966CA-52  |
| 30       | 16     | 45       | 42         | M8×8      | SC 3016□     | EA966C-30 | EA966CA-53  |
|          | 20     | 49       | 42         | M8×8      | SC 3020□     | —         | EA966CA-54  |
| 32       | 20     | 53       | 44         | M8×8      | SC 3220□     | EA966C-32 | —           |
| 35       | 20     | 59       | 47         | M8×8      | SC 3520□     | —         | EA966CA-55  |
| 38       | 22     | 64       | 50         | M10×12    | SC 3822□     | EA966C-34 | —           |
| 40       | 22     | 72       | 55         | M10×12    | SC 4022□     | EA966C-35 | EA966CA-56  |
| 45       | 22     | 75       | 60         | M10×12    | SC 4522□     | EA966C-36 | EA966CA-57  |
| 50       | 25     | 79       | 65         | M10×12    | SC 5025□     | EA966C-37 | EA966CA-58  |