


省エネタイプブイベルト EA967BN-40 ~ -120

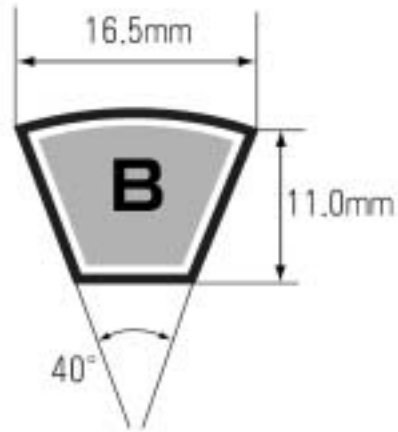

ノッチ形状になっており、屈曲性にすぐれています。
そのため、従来の標準Vベルトに比べて曲げによる動力損失が少なく、省エネ効果があります。

品番	規格	有効ピッチ週長さ
EA967BN-40	BN40	1016mm
EA967BN-41	BN41	1041mm
EA967BN-42	BN42	1067mm
EA967BN-43	BN43	1092mm
EA967BN-44	BN44	1118mm
EA967BN-45	BN45	1143mm
EA967BN-46	BN46	1168mm
EA967BN-47	BN47	1194mm
EA967BN-48	BN48	1219mm
EA967BN-49	BN49	1245mm
品番	規格	有効ピッチ週長さ
EA967BN-50	BN50	1270mm
EA967BN-51	BN51	1295mm
EA967BN-52	BN52	1321mm
EA967BN-53	BN53	1346mm
EA967BN-54	BN54	1372mm
EA967BN-55	BN55	1397mm
EA967BN-56	BN56	1422mm
EA967BN-57	BN57	1448mm
EA967BN-58	BN58	1473mm
EA967BN-59	BN59	1499mm
品番	規格	有効ピッチ週長さ
EA967BN-60	BN60	1524mm
EA967BN-61	BN61	1549mm
EA967BN-62	BN62	1575mm
EA967BN-63	BN63	1600mm
EA967BN-64	BN64	1626mm
EA967BN-65	BN65	1651mm
EA967BN-66	BN66	1676mm
EA967BN-67	BN67	1702mm
EA967BN-68	BN68	1727mm
EA967BN-69	BN69	1753mm
品番	規格	有効ピッチ週長さ
EA967BN-70	BN70	1778mm
EA967BN-71	BN71	1803mm
EA967BN-72	BN72	1829mm
EA967BN-73	BN73	1854mm
EA967BN-74	BN74	1880mm
EA967BN-75	BN75	1905mm
EA967BN-76	BN76	1930mm
EA967BN-77	BN77	1956mm
EA967BN-78	BN78	1981mm
EA967BN-79	BN79	2007mm

品番	規格	有効ピッチ週長さ
EA967BN-80	BN80	2032mm
EA967BN-81	BN81	2057mm
EA967BN-82	BN82	2083mm
EA967BN-83	BN83	2108mm
EA967BN-84	BN84	2134mm
EA967BN-85	BN85	2159mm
EA967BN-86	BN86	2184mm
EA967BN-87	BN87	2210mm
EA967BN-88	BN88	2235mm
EA967BN-89	BN89	2261mm
品番	規格	有効ピッチ週長さ
EA967BN-90	BN90	2286mm
EA967BN-91	BN91	2311mm
EA967BN-92	BN92	2337mm
EA967BN-93	BN93	2362mm
EA967BN-94	BN94	2388mm
EA967BN-95	BN95	2413mm
EA967BN-96	BN96	2438mm
EA967BN-97	BN97	2464mm
EA967BN-98	BN98	2489mm
EA967BN-99	BN99	2515mm
品番	規格	有効ピッチ週長さ
EA967BN-100	BN100	2540mm
EA967BN-101	BN101	2565mm
EA967BN-102	BN102	2591mm
EA967BN-103	BN103	2616mm
EA967BN-104	BN104	2642mm
EA967BN-105	BN105	2667mm
EA967BN-106	BN106	2692mm
EA967BN-107	BN107	2718mm
EA967BN-108	BN108	2743mm
EA967BN-109	BN109	2769mm
品番	規格	有効ピッチ週長さ
EA967BN-110	BN110	2794mm
EA967BN-111	BN111	2819mm
EA967BN-112	BN112	2845mm
EA967BN-113	BN113	2870mm
EA967BN-114	BN114	2896mm
EA967BN-115	BN115	2921mm
EA967BN-116	BN116	2946mm
EA967BN-117	BN117	2972mm
EA967BN-118	BN118	2997mm
EA967BN-119	BN119	3023mm
EA967BN-120	BN120	3048mm

規格 × 25.4mm = 有効ピッチ長さ