


ポリエステルスリング

EA981TA-0.5~10、TB-0.5~10、TC-1.5~10
 TD-0.5~10、RK-1.5~10、RL-1.5~10

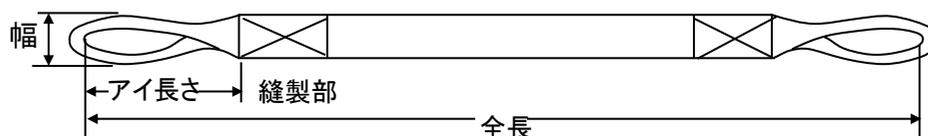

- 材質…ポリエステル
- 表面は青色ですが、芯材は白色です。芯材の白色が見えたら寿命ですので品質管理に有効です。



取扱中止

取扱中止

取扱中止

取扱中止

取扱中止

取扱中止

品番	揚量	全長 (m)	アイ長さ (mm)	アイ(mm)		縫製部(mm)		本体(mm)	
				幅	太さ	幅	太さ	幅	太さ
EA981TA-0.5	(幅)25mm (0.8t)	0.5	150	27	6	25	12	25	8
EA981TA-1		1.0	220						
EA981TA-1.5		1.5							
EA981TA-2		2.0							
EA981TA-2.5		2.5							
EA981TA-3		3.0							
EA981TA-3.5		3.5							
EA981TA-4		4.0							
EA981TA-5		5.0							
EA981TA-6		6.0							
EA981TA-8	8.0								
EA981TA-10	10.0								
EA981TD-0.5	(幅)35mm (1.25t)	0.5	150	37	6	35	12	35	8
EA981TD-1		1.0	220						
EA981TD-1.5		1.5							
EA981TD-2		2.0							
EA981TD-2.5		2.5							
EA981TD-3		3.0							
EA981TD-3.5		3.5							
EA981TD-4		4.0							
EA981TD-5		5.0							
EA981TD-6		6.0							
EA981TD-7	7.0								
EA981TD-8	8.0								
EA981TD-9	9.0								
EA981TD-10	10.0								
EA981TB-0.5	(幅)50mm (1.6t)	0.5	150	27	14	50	12	50	8
EA981TB-1		1.0	300						
EA981TB-1.5		1.5							
EA981TB-2		2.0							
EA981TB-2.5		2.5							
EA981TB-3		3.0							
EA981TB-3.5		3.5							
EA981TB-4		4.0							
EA981TB-5		5.0							
EA981TB-6		6.0							
EA981TB-8	8.0								
EA981TB-10	10.0								

