

POLYTEX® lashing strap system **RS 4000**

Stable lashing system for moderately heavy loads in industry and handicrafts.
With ratchet lever transport lock.
Strap width 35 mm
Pre-tensioning force S_{TF} 100 daN



Ideal for light loads

Lashing method

Permissible lashing force LC (daN)	2000	2000	1000
Breaking force BF (daN)	4000	4000	2000

one-piece	Availability	
	4 m	6 m
Reference no. 123464	EA982CG-4 ✓	EA982CG-6 ✓


two-piece with eye hooks	Availability	
	4 m	6 m
Reference no. 123486	✓	✓

two-piece with claw hooks	Availability	
	4 m	6 m
Reference no. 123475	✓	✓

two-piece with wire claw hooks	Availability	
	4 m	6 m
Reference no. 123472	✓	✓

two-piece with wire claw hooks with safety latch	Availability	
	4 m	6 m
Reference no. 241817 new	✓	✓

two-piece with J-hooks	Availability	
	4 m	6 m
Reference no. 123481	EA982CB-4 ✓	EA982CB-6 ✓

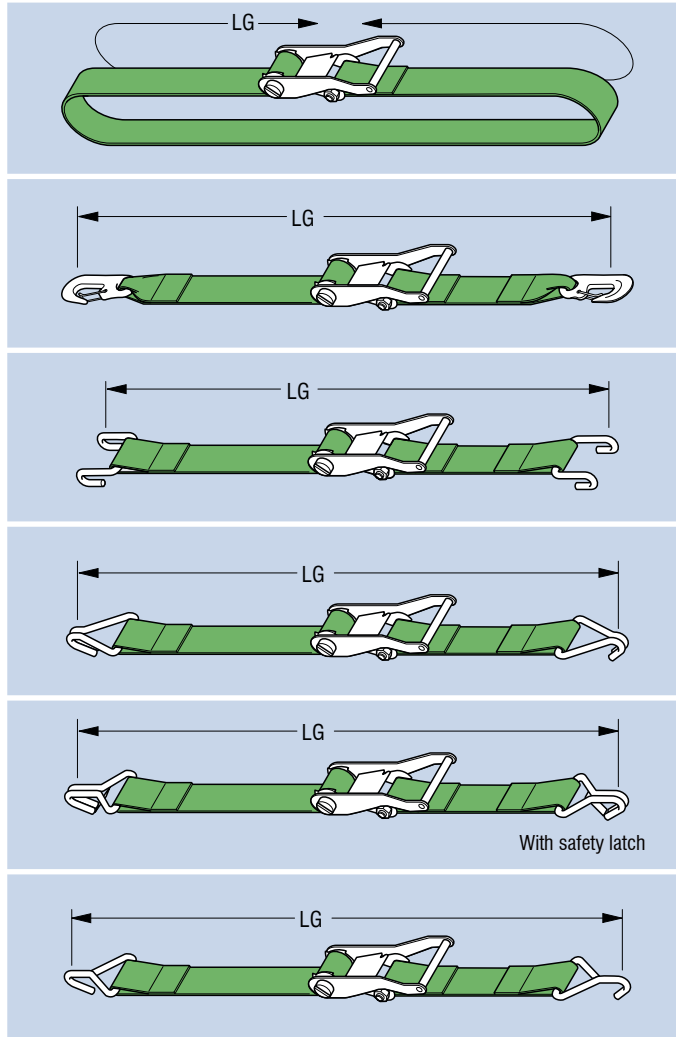

Please always specify the reference number and length LG when ordering!
Additional lengths on enquiry.

... and for suitable protective systems:

POLYTEX® abrasion protection sleeve See page 136	POLYTEX® edge protection profile, plastic See page 256	POLYTEX® edge protection profile, steel See page 256

Cargo lashing equipment

