


POLYTEX® lashing strap system **RS 10 000**

Particularly stable lashing system for heavy load units of all kinds, with extra-strong strap.
With ratchet lever transport lock.
Strap width 50 mm
Pre-tensioning force S_{Tr} 250 daN



The standard - universally usable

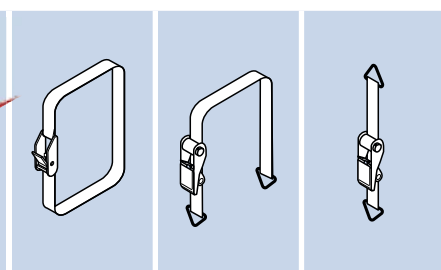

Lashing method

Permissible lashing force LC (daN)	5000	5000	2500
Breaking force BF (daN)	10000	10000	5000

one-piece	Availability	
	8 m	10 m
Reference no. 123276	EA982CH-8 ✓	EA982CH-10 ✓

two-piece with latched snap hook	Availability	
	8 m	10 m
Reference no. 123286	✓	✓


two-piece with triangular hooks	Availability	
	8 m	10 m
Reference no. 123320	EA982CC-8B ✓	✓

two-piece with claw hooks	Availability	
	8 m	10 m
Reference no. 123304	✓	✓

two-piece with wire claw hooks	Availability	
	8 m	10 m
Reference no. 123327	✓	✓

two-piece with wire claw hooks with safety latch	Availability	
	8 m	10 m
Reference no. 123334	✓	✓

two-piece with J-hooks	Availability	
	8 m	10 m
Reference no. 123331	✓	✓

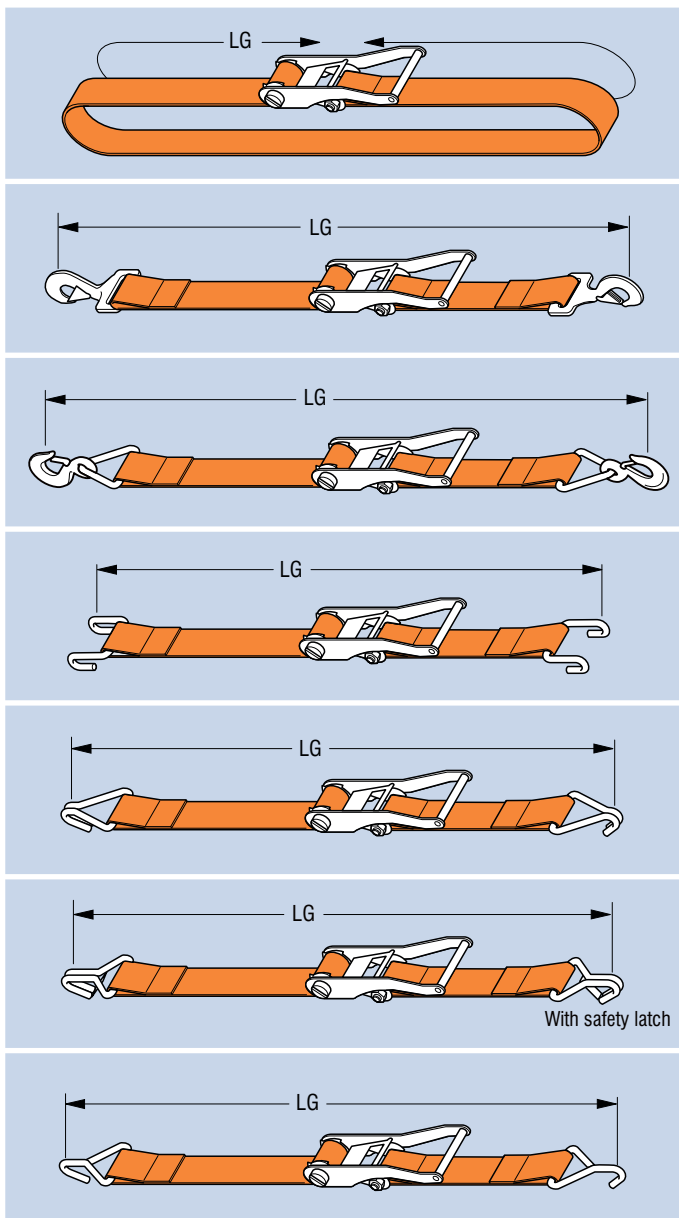

Please always specify the reference number and length LG when ordering!
Additional lengths on enquiry.

... and for suitable protective systems:

POLYTEX® Flexoclip S See page 135	POLYTEX® abrasion protection sleeve See page 136	POLYTEX® edge protection plate See page 256	POLYTEX® edge protection profile, plastic See page 256	POLYTEX® edge protection profile, steel See page 256

Cargo lashing equipment

