




# 樹脂キャップ 角パイプ用

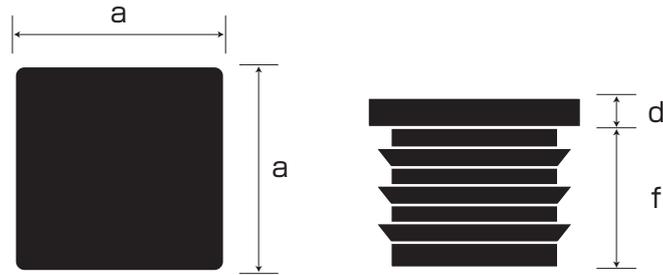


品番	材質	適合パイプ 内径	a (mm)	b (mm)	c (mm)	d (mm)	e (mm)	f (mm)	g (mm)	サイズ (mm)	備考
角パイプ用											
AC316	PE	10.8×10.8	13			3.5		12		□12用	
EA983FP-71	PE	13.8×13.8	16			4.2		14		□15用	
AC318	PE	16.8×16.8	19.1			4.9		13.9		□19用	
EA983FP-72	PE	17.2×17.2	20			4		14		□20用	
EA983FP-81	PE	22.8×22.8	25.1			4		15		□25用	
EA983FP-73	PE	27.2×27.2	30			4		15		□30用	
EA983FP-82	PE	36.8×36.8	40			6		23.3		□40用	
EA983FP-74	PP	46.8×46.8	50.2			5		18		□50用	
EA983FP-83	PE	56.8×56.8	60			6		21.5		□60用	
EA983FP-84	PP	70.4×70.4	75.5			5		18		□75用	
EA983FP-85	PP	95.4×95.4	100.2			5		18		□100用	

樹脂キャップ



# 樹脂キャップ 平角パイプ用

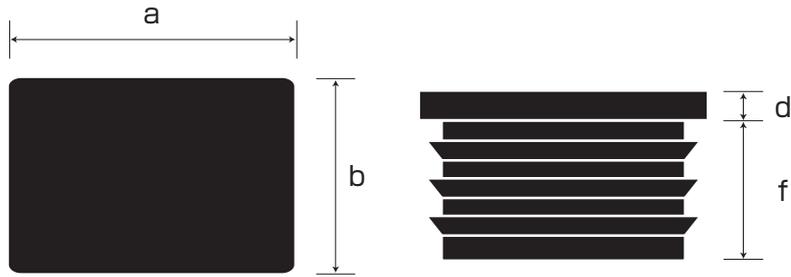

品番	材質	適合パイプ 内径	a (mm)	b (mm)	c (mm)	d (mm)	e (mm)	f (mm)	g (mm)	サイズ (mm)	備考
平角パイプ用											
AC328	PE	22.6×9.6	25	12.1		5.2		12		□25×15用	
AC329	PE	27.2×13.2	29.7	15.8		5		15		□30×15用	
EA983FP-91	PE	27.6×17.6	30	20		3.2		17		□30×20用	
EA983FP-92	PE	37.6×17.6	40	20		5		13		□40×20用	
AC330	PE	46.8×22.8	50.1	26.1		2.1		8.5		□50×25用	
AC323	PE	46.8×26.8	50.2	30.5		5		22		□50×30用	
EA983FP-93	PE	56.8×26.8	60.1	30.3		4.9		30.5		□60×30用	
AC325	PE	66.8×26.8	70	30		5		15		□70×30用	
AC327	PE	96.6×46.6	100.4	50.2		5		20		□100×50用	