



## Rubber Wheel Chocks

- Strong and safe in industrial applications—ideal for construction, utility, and other commercial industries
- Durable rubber is resistant to UV, moisture, salt, and oil damage
- Traction design grips the tire and road without causing damage
- Designed to position either side against tire



## RC450

Standard of the utility industry

- Includes a steel loop carrying handle
- Available in 3 base options
- Fits most chock storage compartments



RC450-S



RC450



RC450-S



RC450-CL

Model	Description	Length	Width	Height	Weight	Prop 65
RC450	Bottom Void, Steel Loop	10 in (25.4 cm)	8 in (20.3 cm)	5.5 in (14.0 cm)	7 lb (3.2 kg)	—
RC450-S	Solid Bottom, Steel Loop				10 lb (4.5 kg)	
RC450-CL	Bottom Void and Aluminum Ice Cleat, Steel Loop				8.5 lb (3.9 kg)	

## RC815

For "over the road" trucks and trailers and loading dock facilities

- Ribbed pyramid design
- Eyebolt for ropes or chains
- Ideal for keeping truck trailers in place during loading or unloading




RC815

Model	Description	Length	Width	Height	Weight	Prop 65
RC815	Wheel Chock with Bottom Void	10 in (25.4 cm)	8 in (20.3 cm)	6 in (15.2 cm)	8.5 lb (3.9 kg)	—

## RC915

For heavy trucks, trailers and road construction equipment

- Ribbed pyramid design
- Eyebolt for ropes or chains

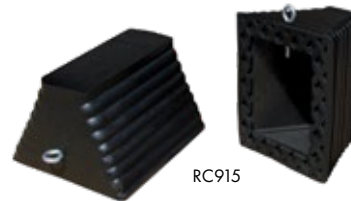

RC915

Model	Description	Length	Width	Height	Weight	Prop 65
RC915	Wheel Chock with Bottom Void	11.5 in (29.2 cm)	10 in (25.4 cm)	7.25 in (18.4 cm)	15 lb (6.8 kg)	—

## RC5500

Triangular design used by aircrafts worldwide

- High-density rubber is resistant to the elements
- Horizontal traction ribs
- Replaceable 24 in (61.0 cm) rope lanyard (contact Customer Service)
- Sold as singles with rope or roped together as pairs



RC5500-P

RC5500-S

Model (single)	Model (pair)	Length	Width	Height	Weight (single)	Prop 65
RC5510S	RC5510P	10 in (25.4 cm)	5 in (12.7 cm)	4.33 in (11.0 cm)	6.5 lb (3.0 kg)	—
RC5512S	RC5512P	12 in (30.5 cm)	5 in (12.7 cm)	4.33 in (11.0 cm)	7.7 lb (3.5 kg)	—
RC5515S	RC5515P	15 in (38.1 cm)	5 in (12.7 cm)	4.33 in (11.0 cm)	9.3 lb (4.2 kg)	—
RC5518S	RC5518P	18 in (45.7 cm)	5 in (12.7 cm)	4.33 in (11.0 cm)	11 lb (5.0 kg)	—
RC5521S	RC5521P	21 in (53.3 cm)	5 in (12.7 cm)	4.33 in (11.0 cm)	12.7 lb (5.8 kg)	—
RC5524S	RC5524P	24 in (61.0 cm)	5 in (12.7 cm)	4.33 in (11.0 cm)	14.4 lb (6.5 kg)	—

## Checkers

620 Compton St  
 Broomfield, CO 80020

**Phone:** (800) 438-9336

**Fax:** (720) 890-4858

**Email:** sales@checkers-safety.com

Checkers-Safety.com