

# Product Data Sheet



## L-VW 125R

**EAN** 4047526561697  
**ID** 561696

**Pressed steel swivel castor, medium heavy duty brackets, with top plate fitting, Wheels with 'Blickle Soft' soft rubber tyres, with pressed steel rim**

**Bracket:**

Made of pressed steel, with double ball bearing in the swivel head, ball protection by the special top plate and ball disc design. The special Blickle dynamic riveting process of the swivel head results in minimal swivel head play and smooth rolling characteristics with an increased service life achieved by the work hardening of the ball race grooves. Bolted wheel axle. Zinc-plated, blue-passivated, Cr6-free.

**Wheels:**

Made of 'Blickle Soft' highly elastic soft rubber, round profile, highest operational comfort, exceptionally low-noise operation, excellent floor preservation.

**Tread/tyre:** Made of "Blickle Soft" soft rubber.

**Tread colours:** black

**Wheel centre/rim:**

Pressed steel rim with tubular steel hub, pressed rim (special shock and impact-resistant design), zinc-plated, blue-passivated, Cr6-free. Tyre pressed with rim.

**Wheel centre colour:** blue passivated



**Rolling resistance**

■ ■ ■ □ □ Good

**Operating noise**

■ ■ ■ ■ ■ Excellent

**Floor surface preservation**


■ ■ ■ ■ ■ Excellent

# Product Data Sheet



## Technical data

Plate size		100 x 85
Bolt hole spacing		80 x 60
Bolt hole Ø		9
Wheel Ø		125 mm (D)
Tyre width		37,5 mm (T2)
Load capacity		50 kg
Total height		150 mm (H)
Offset swivel castor		40 mm
unit weight		1,1 kg
Temperature resistance		-25 ° C
Temperature resistance to		80 ° C
tread and tyre hardness		50° Shore A
Bearing type:		Roller bearing

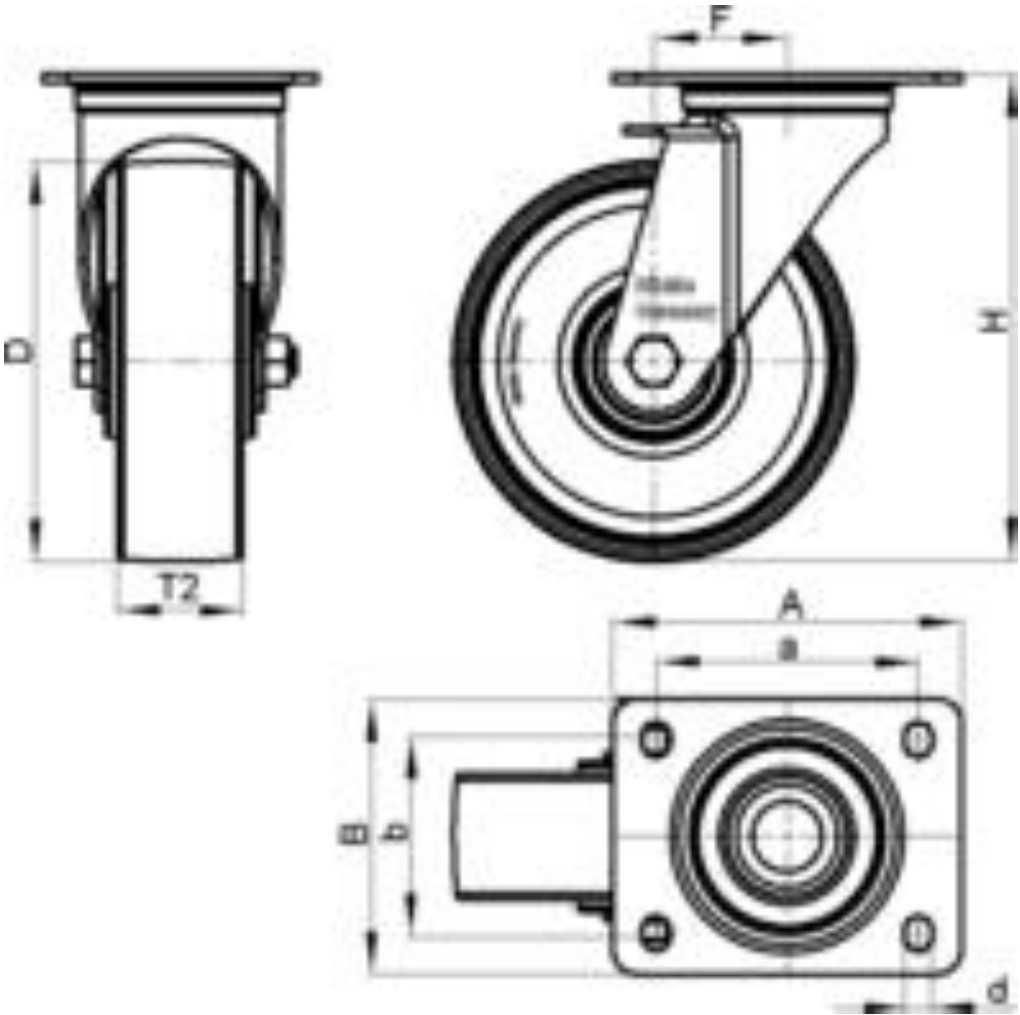



# Product Data Sheet



Variants	
	<p><b>L-VW 125R-FA</b></p> <p>Pressed steel swivel castor, medium heavy duty brackets, with top plate fitting, Wheels with 'Blickle Soft' soft rubber tyres, with pressed steel rim</p>
	<p><b>L-VW 125R-FI</b></p> <p>Pressed steel swivel castor, medium heavy duty brackets, with top plate fitting and 'stop-fix' brake, Wheels with 'Blickle Soft' soft rubber tyres, with pressed steel rim</p>
	<p><b>L-VW 125R-FI-FA</b></p> <p>Pressed steel swivel castor, medium heavy duty brackets, with top plate fitting and 'stop-fix' brake, Wheels with 'Blickle Soft' soft rubber tyres, with pressed steel rim</p>
	<p><b>L-VW 125R-FI-SG</b></p> <p>Pressed steel swivel castor, medium heavy duty brackets, with top plate fitting and 'stop-fix' brake, Wheels with 'Blickle Soft' soft rubber tyres, with pressed steel rim</p>
	<p><b>L-VW 125R-FI-SG-FA</b></p> <p>Pressed steel swivel castor, medium heavy duty brackets, with top plate fitting and 'stop-fix' brake, Wheels with 'Blickle Soft' soft rubber tyres, with pressed steel rim</p>
	<p><b>L-VW 125R-SG</b></p> <p>Pressed steel swivel castor, medium heavy duty brackets, with top plate fitting, Wheels with 'Blickle Soft' soft rubber tyres, with pressed steel rim</p>
	<p><b>L-VW 125R-SG-FA</b></p> <p>Pressed steel swivel castor, medium heavy duty brackets, with top plate fitting, Wheels with 'Blickle Soft' soft rubber tyres, with pressed steel rim</p>
	<p><b>L-VW 125R-ST</b></p> <p>Pressed steel swivel castor, medium heavy duty brackets, with top plate fitting and 'stop-top' brake, Wheels with 'Blickle Soft' soft rubber tyres, with pressed steel rim</p>
	<p><b>L-VW 125R-ST-FA</b></p> <p>Pressed steel swivel castor, medium heavy duty brackets, with top plate fitting and 'stop-top' brake, Wheels with 'Blickle Soft' soft rubber tyres, with pressed steel rim</p>
	<p><b>L-VW 125R-ST-SG</b></p> <p>Pressed steel swivel castor, medium heavy duty brackets, with top plate fitting and 'stop-top' brake, Wheels with 'Blickle Soft' soft rubber tyres, with pressed steel rim</p>

# Product Data Sheet



## Variants



### L-VW 125R-ST-SG-FA

Pressed steel swivel castor, medium heavy duty brackets, with top plate fitting and 'stop-top' brake, Wheels with 'Blickle Soft' soft rubber tyres, with pressed steel rim

## Option:



### RI-03.01

Directional lock