

Product Data Sheet



B-VW 202R

EAN 4047526566722

ID 566729

Pressed steel fixed castor, medium duty brackets, with top plate fitting, Wheels with 'Blickle Soft' soft rubber tyres, with pressed steel rim

Bracket:

Made of pressed steel. Bolted wheel axle. Zinc-plated, blue-passivated, Cr6-free.

Wheels:

Made of 'Blickle Soft' highly elastic soft rubber, round profile, highest operational comfort, exceptionally low-noise operation, excellent floor preservation.

Tread/tyre: Made of "Blickle Soft" soft rubber.

Tread colours black

Wheel centre/rim:

Pressed steel rim with tubular steel hub, pressed rim (special shock and impact-resistant design), zinc-plated, blue-passivated, Cr6-free. Tyre pressed with rim.

Wheel centre colour: blue passivated



Rolling resistance

■■■■□□ Good

Operating noise

■■■■■■ Excellent





 

 
 

 

Floor surface preservation

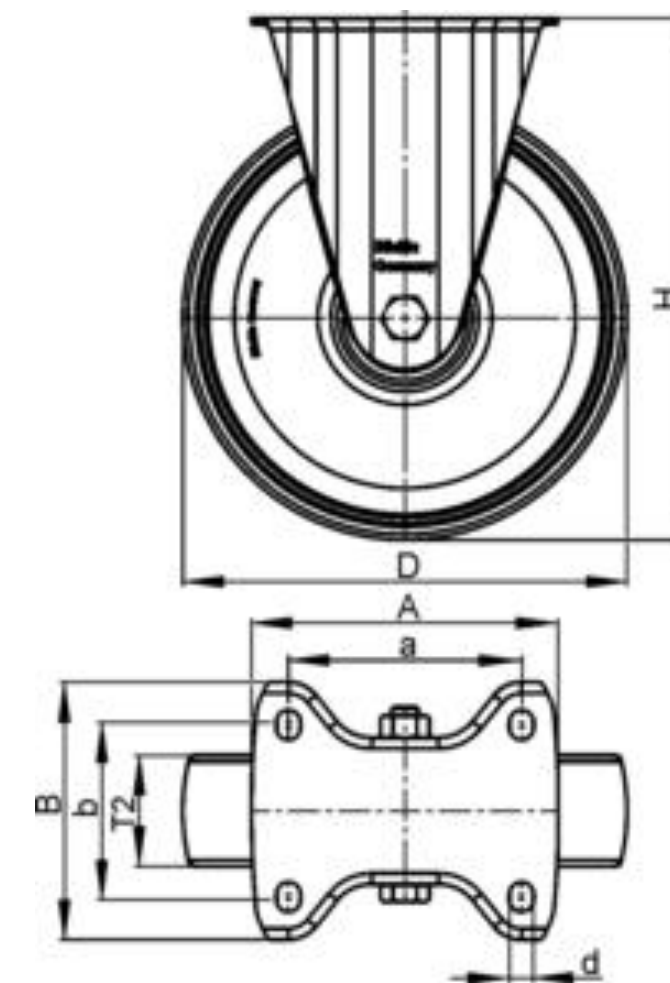
■■■■■■ Excellent

Product Data Sheet



Technical data

Plate size		140 x 110
Bolt hole spacing		105 x 75-80
Bolt hole Ø		11
Wheel Ø		200 mm (D)
Wheel width		50 mm (T2)
Load capacity		100 kg
Total height		235 mm (H)
unit weight		2,5 kg
Temperature resistance		-25 ° C
Temperature resistance to		80 ° C
tread and tyre hardness		50° Shore A
Bearing type:		Roller bearing



Product Data Sheet



Variants



B-VW 202R-FA

Pressed steel fixed castor, medium duty brackets, with top plate fitting, Wheels with 'Blickle Soft' soft rubber tyres, with pressed steel rim



B-VW 202R-SG

Pressed steel fixed castor, medium duty brackets, with top plate fitting, Wheels with 'Blickle Soft' soft rubber tyres, with pressed steel rim



B-VW 202R-SG-FA

Pressed steel fixed castor, medium duty brackets, with top plate fitting, Wheels with 'Blickle Soft' soft rubber tyres, with pressed steel rim