

## EA986GB-200



EAN: 4047526042547

ID: 42549

**Pressed steel swivel castor, medium heavy duty brackets, with top plate fitting, Wheels with 'Blickle Comfort' two-component solid rubber tyres, with pressed steel rim**


**Bracket:**

Made of heavy pressed steel, with double ball bearing in the swivel head, strong central kingpin, swivel head seals. The special Blickle dynamic riveting process of the swivel head results in minimal swivel head play and smooth rolling characteristics with an increased service life achieved by the work hardening of the ball race grooves. Bolted wheel axle. Zinc-plated, blue-passivated, Cr6-free.

**Wheels:**

**Tyre & running tread:** Made of 'Blickle Comfort' two-component solid rubber, with hard rubber core and highly elastic rubber tread, very high operational comfort, low-noise operation, compared to standard solid rubber the operational comfort and the load capacity are increased whereas the rolling resistance is reduced, very good floor preservation. Tread colour: black

**Rim / wheel centre:** Pressed steel rim with tubular steel hub, pressed rim (special shock and impact-resistant design), zinc-plated, blue-passivated, Cr6-free. Tyre pressed with rim.

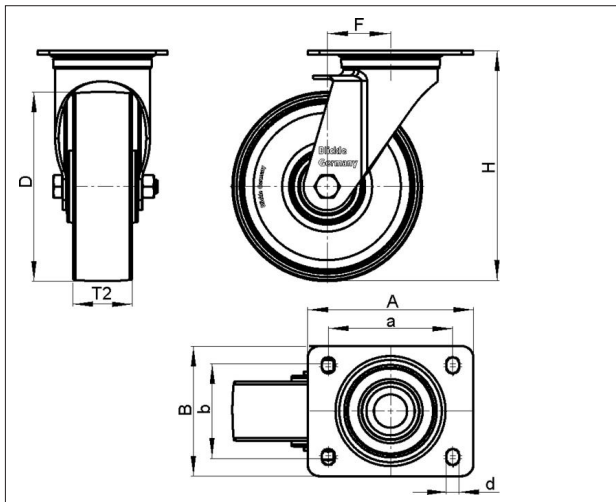

## Technical data

Wheel Ø (D)	200 mm
Wheel width (T2)	50 mm
Load capacity	350 kg
Total height (H)	235 mm
Offset swvl castor (F)	65 mm
Unit weight	3.35 kg
Temperature range from	-25 °C
Temperature range to	80 °C
Tread & tyre hardness	65° Shore A
Bearing type	
Plate size (A,B)	140 x 110 mm
Bolt hole Ø (d)	11 mm
Bolt hole spacing (a,b)	105 x 75-80 mm

Rolling resistance



Operating noise



Floor surface preservation

**Blickle Räder+Rollen GmbH u. Co. KG**

Heinrich-Blickle-Straße 1 · 72348 Rosenfeld · Germany  
 Telefon: +49 7428 932-0 · Telefax: +49 7428 932-209  
 E-Mail: [info@blickle.com](mailto:info@blickle.com) · Internet: [www.blickle.com](http://www.blickle.com)

© Blickle Räder+Rollen GmbH u. Co. KG 2013  
 Rosenfeld · Germany

**L-RD 202R**

Variants	
	With central braking system 'central-stop'
	With pressed steel thread guard, zinc-plated
	With 'stop-top' brake
	With non-marking grey tyre, 56° shore A