

EA986GH-50



EAN: 4047526275723

ID: 275727

Light duty swivel castor with top plate fitting, Wheel with solid rubber tyres, with synthetic rim


Bracket:

Made of pressed steel, with double ball bearing in the swivel head, ball protection by the special top plate and ball disc design. The special Blickle dynamic riveting process of the swivel head results in minimal swivel head play and smooth rolling characteristics with an increased service life achieved by the work hardening of the ball race grooves. Bolted wheel axle. Zinc-plated, blue-passivated, Cr6-free.

Wheels:

Tyre & running tread: Made of high-quality solid rubber, very high operational comfort, low-noise operation, very good floor preservation. Tread colour: dark grey

Rim / wheel centre: Made of high-quality, impact-resistant nylon. Pressed-on tyre.

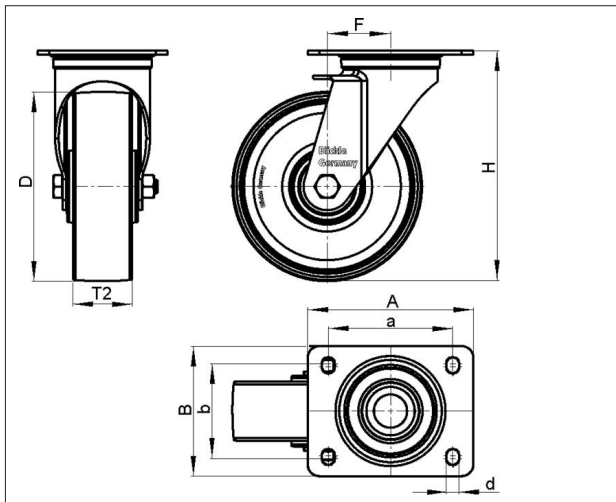

Technical data

Wheel Ø (D)	50 mm
Wheel width (T2)	18 mm
Load capacity	40 kg
Total height (H)	71 mm
Offset swvl castor (F)	25 mm
Unit weight	0.238 kg
Temperature range from	-20 °C
Temperature range to	60 °C
Tread & tyre hardness	80° Shore A
Bearing type	
Plate size (A,B)	60 x 60 mm
Bolt hole Ø (d)	6,2 mm
Bolt hole spacing (a,b)	38x38/48x48 mm

Rolling resistance



Operating noise



Floor surface preservation



Blickle Räder+Rollen GmbH u. Co. KG

Heinrich-Blickle-Straße 1 · 72348 Rosenfeld · Germany

Telefon: +49 7428 932-0 · Telefax: +49 7428 932-209

E-Mail: info@blickle.com · Internet: www.blickle.com

© Blickle Räder+Rollen GmbH u. Co. KG 2013
Rosenfeld · Germany

LPA-VPA 50K

Variants



Antistatic version