

# Product Data Sheet



## LI-VEHI 125R

**EAN** 4047526612528  
**ID** 612523

**Heat-resistant pressed steel swivel castor with top plate fitting, Heat-resistant Blickle TempLine® Basic wheel with solid rubber tyres, with pressed steel rim**

**Bracket:**

Made of pressed steel, with double ball bearing in the swivel head, strong central kingpin, ball protection by the special top plate design. The special Blickle dynamic riveting process of the swivel head results in smooth rolling characteristics, increased service life and the swivel head play is set specifically for high temperature applications, with special heat-resistant grease. Bolted wheel axle. Zinc-plated, blue-passivated, Cr6-free.



**Wheels:**

Made of standard solid rubber, very high operational comfort, low-noise operation, very good floor preservation, PAH conform acc. to EU directive 2005/69/EC.

**Tread/tyre:** Made of heat-resistant solid rubber.

**Tread colours** black

**Wheel centre/rim:**

Pressed steel rim, zinc-plated, blue-passivated, Cr6-free.

**Wheel centre colour:** blue passivated

**Rolling resistance**

■ ■ □ □ □ Satisfactory

**Operating noise**

■ ■ ■ ■ □ Very good

**Floor surface preservation**


■ ■ ■ ■ □ Very good

# Product Data Sheet



## Technical data

Plate size		100 x 85
Bolt hole spacing		80 x 60
Bolt hole Ø		9
Wheel Ø		125 mm (D)
Tyre width		37,5 mm (T2)
Load capacity		90 kg
Total height		150 mm (H)
Offset swivel castor		40 mm
unit weight		1 kg
Temperature resistance		-25 ° C
Temperature resistance to		200 ° C
tread and tyre hardness		80° Shore A
Bearing type:		Roller bearing

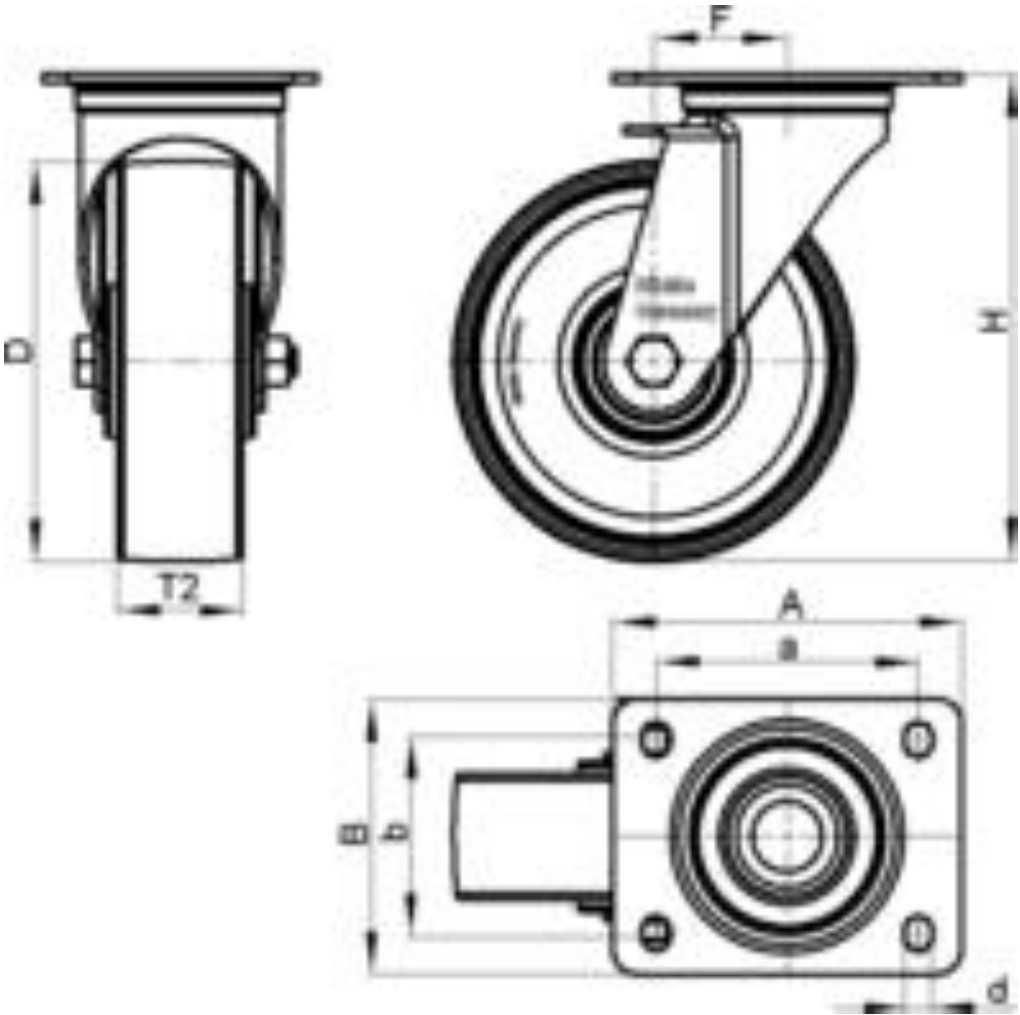

# Product Data Sheet



## Variants



### LI-VEHI 125R-FI

Heat-resistant pressed steel swivel castor with top plate fitting and 'stop-fix' brake, Heat-resistant Blickle TempLine® Basic wheel with solid rubber tyres, with pressed steel rim