

EA986GN-50




EAN: 4047526574581

ID: 574582

Wheel with thermoplastic rubber tread, with polypropylene wheel centre

Tyre & running tread: Made of high-quality thermoplastic rubber elastomer (TPE), high operational comfort, low-noise operation, low rolling and swivelling resistance, good floor preservation, chemically bonded for an inseparable connection to the wheel centre. Tread colour: grey

Rim / wheel centre: Made of high-quality, impact-resistant polypropylene. Chemically bonded.

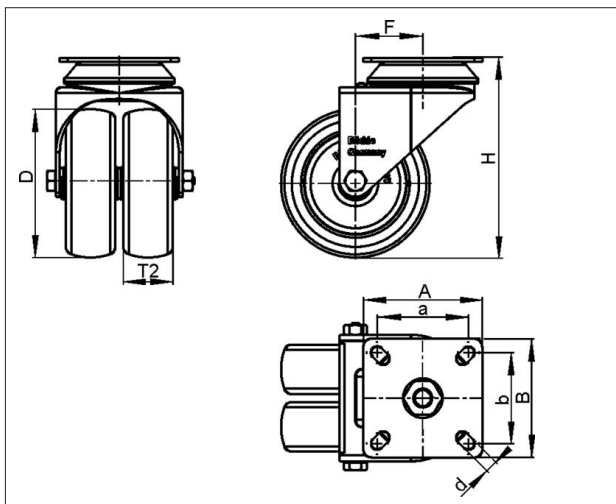

Technical data

Wheel Ø (D)	50 mm
Wheel width (T2)	2 x 19 mm
Load capacity	80 kg
Total height (H)	71 mm
Offset swvl castor (F)	31 mm
Unit weight	0.265 kg
Temperature range from	-20 °C
Temperature range to	60 °C
Tread & tyre hardness	85° Shore A
Bearing type	
Plate size (A,B)	60 x 60 mm
Bolt hole Ø (d)	6,2 mm
Bolt hole spacing (a,b)	38x38/48x48 mm

Rolling resistance



Operating noise



Floor surface preservation



Blickle Räder+Rollen GmbH u. Co. KG

Heinrich-Blickle-Straße 1 · 72348 Rosenfeld · Germany

Telefon: +49 7428 932-0 · Telefax: +49 7428 932-209

E-Mail: info@blickle.com · Internet: www.blickle.com

© Blickle Räder+Rollen GmbH u. Co. KG 2013
Rosenfeld · Germany

LDA-TPA 50K-FK

Variants



Electrically conductive
version, non-marking