

## EA986GN-75




**EAN: 4047526574635**

**ID: 574632**

**Wheel with thermoplastic rubber tread, with polypropylene wheel centre**

**Tyre & running tread:** Made of high-quality thermoplastic rubber elastomer (TPE), high operational comfort, low-noise operation, low rolling and swivelling resistance, good floor preservation, chemically bonded for an inseparable connection to the wheel centre. Tread colour: grey

**Rim / wheel centre:** Made of high-quality, impact-resistant polypropylene. Chemically bonded.

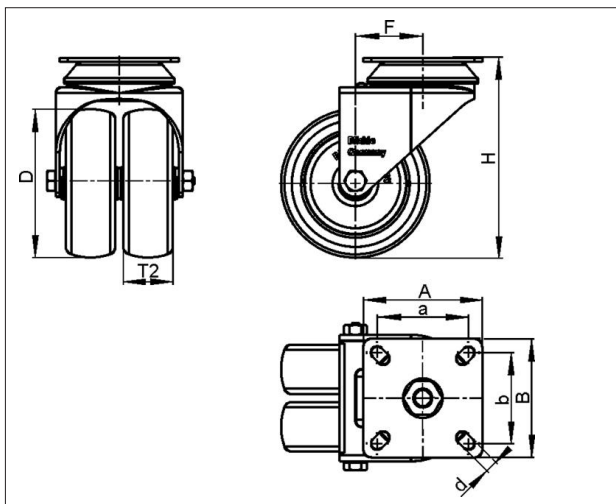

### Technical data

|                         |                |
|-------------------------|----------------|
| Wheel Ø (D)             | 75 mm          |
| Wheel width (T2)        | 2 x 25 mm      |
| Load capacity           | 100 kg         |
| Total height (H)        | 101 mm         |
| Offset swvl castor (F)  | 34 mm          |
| Unit weight             | 0.597 kg       |
| Temperature range from  | -20 °C         |
| Temperature range to    | 60 °C          |
| Tread & tyre hardness   | 85° Shore A    |
| Bearing type            |                |
| Plate size (A,B)        | 60 x 60 mm     |
| Bolt hole Ø (d)         | 6,2 mm         |
| Bolt hole spacing (a,b) | 40x40/46x46 mm |

Rolling resistance



Operating noise



Floor surface preservation



## LDA-TPA 75K-FK

### Variants



Electrically conductive  
version, non-marking