

Product Data Sheet



LDA-POA 50G

EAN 4047526106706
ID 106708

Light duty twin wheel swivel castor with top plate fitting, Nylon wheel

Bracket:

Made of pressed steel, with double ball bearing in the swivel head, ball protection by the special top plate and ball disc design, dynamically pressed swivel head. Bolted wheel axle. Zinc-plated, blue-passivated, Cr6-free.

Wheels:

Made of high-quality, impact-resistant nylon, very low rolling and swivelling resistance, smooth running performance on even floors, very high abrasion resistance.

Tread/tyre: Made of high-quality, impact-resistant nylon.

Tread colours: black

Wheel centre/rim: -

Wheel centre colour: grey



Rolling resistance

■■■■■ Excellent

Operating noise

■■■■ Satisfactory

Floor surface preservation


■■■■ Satisfactory

Product Data Sheet



Technical data

Plate size		60 x 60
Bolt hole spacing		38x38/48x48
Bolt hole Ø		6,2
Wheel Ø		50 mm (D)
Wheel width		2 x 18 mm (T2)
Load capacity		80 kg
Total height		71 mm (H)
Offset swivel castor		31 mm
unit weight		0,2 kg
Temperature resistance		-25 ° C
Temperature resistance to		80 ° C
tread and tyre hardness		70° Shore D
Bearing type		Plain bore

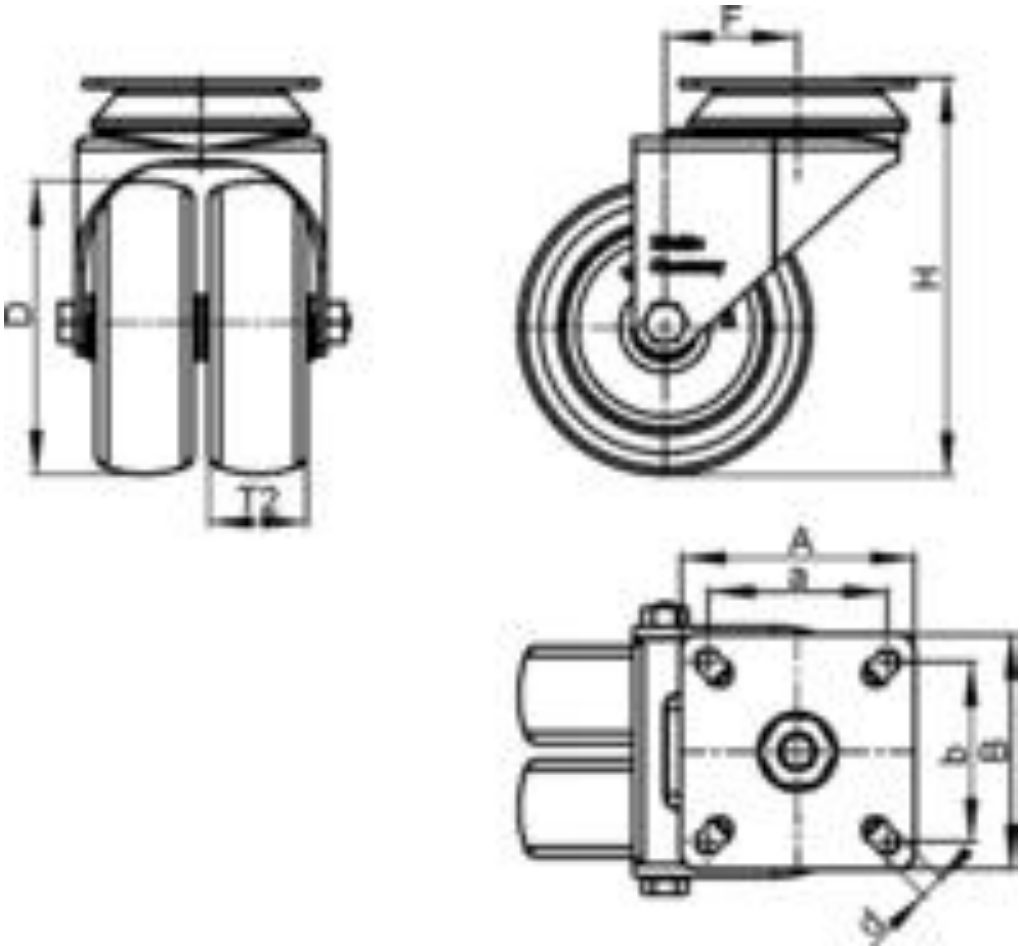

Product Data Sheet



Variants



LDA-POA 50G-FI

Light duty twin wheel swivel castor with top plate fitting and 'stop-fix' brake, Nylon wheel