

EA986GR-75



EAN: 4047526106713

ID: 106716

Light duty twin wheel swivel castor with top plate fitting, Nylon wheel


Bracket:

Made of pressed steel, with double ball bearing in the swivel head, ball protection by the special top plate and ball disc design, dynamically pressed swivel head. Bolted wheel axle. Zinc-plated, blue-passivated, Cr6-free.

Wheels:

Tyre & running tread: Made of high-quality, impact-resistant nylon, very low rolling and swivelling resistance, smooth running performance on even floors, very high abrasion resistance. Tread colour: black

Rim / wheel centre: -

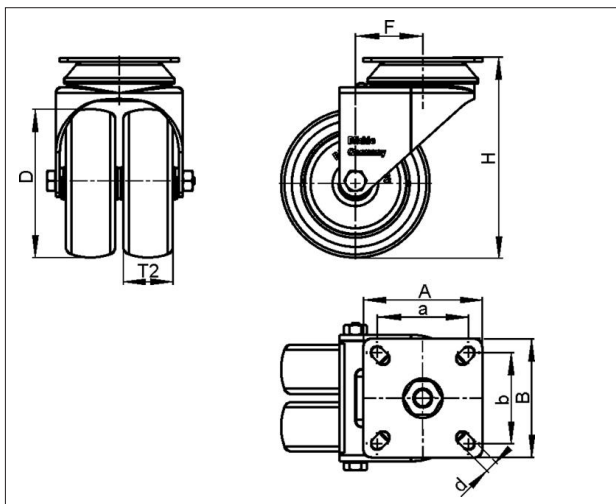

Technical data

Wheel Ø (D)	75 mm
Wheel width (T2)	2 x 23 mm
Load capacity	100 kg
Total height (H)	101 mm
Offset swvl castor (F)	34 mm
Unit weight	0.459 kg
Temperature range from	-25 °C
Temperature range to	80 °C
Tread & tyre hardness	70° Shore D
Bearing type	
Plate size (A,B)	60 x 60 mm
Bolt hole Ø (d)	6,2 mm
Bolt hole spacing (a,b)	40x40/46x46 mm

Rolling resistance



Operating noise



Floor surface preservation

