

Product Data Sheet



BPA-TPA 75K-FK

EAN 4047526567446

ID 567446

Light duty fixed castor with top plate fitting, Wheel with thermoplastic rubber tread, with polypropylene wheel centre

Bracket:

Made of pressed steel. Bolted wheel axle. Zinc-plated, blue-passivated, Cr6-free.

Wheels:

Made of high-quality thermoplastic rubber elastomer (TPE), high operational comfort, low-noise operation, low rolling and swivelling resistance, good floor preservation, chemically bonded for an inseparable connection to the wheel centre.

Tread/tyre:

Made of thermoplastic rubber elastomer (TPE), contains traces of oil.

Tread colours grey

Wheel centre/rim:

Made of high-quality, impact-resistant polypropylene. Chemically bonded.

Wheel centre colour: grey



Rolling resistance

■■■■□ Very good

Operating noise

■■■■□ Good

Floor surface preservation


■■■■□ Good

Product Data Sheet



Technical data

Plate size		60 x 60
Bolt hole spacing		38x38/48x48
Bolt hole Ø		6,2
Wheel Ø		75 mm (D)
Wheel width		25 mm (T2)
Load capacity		75 kg
Total height		100 mm (H)
unit weight		0,3 kg
Temperature resistance		-20 ° C
Temperature resistance to		60 ° C
tread and tyre hardness		85° Shore A
Bearing type:		Ball bearing

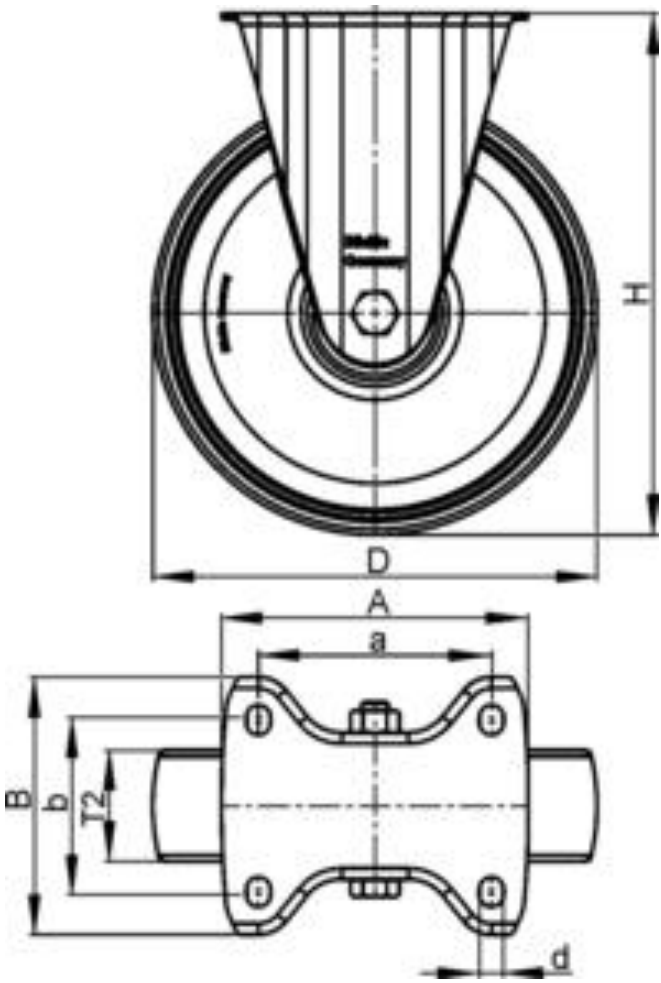

Product Data Sheet



Variants



BPA-TPA 75K-ELS-FK

Light duty fixed castor with top plate fitting, Wheel with thermoplastic rubber tread, with polypropylene wheel centre