

Product Data Sheet



B-VE 125R

EAN 4047526275808

ID 275800

Pressed steel fixed castor with top plate fitting, Wheel with standard solid rubber tyres, with pressed steel rim

Bracket:

Made of pressed steel. Bolted wheel axle. Zinc-plated, blue-passivated, Cr6-free.

Wheels:

Made of standard solid rubber, very high operational comfort, low-noise operation, very good floor preservation, PAH conform acc. to EU directive 2005/69/EC.

Tread/tyre: Made of standard solid rubber.

Tread colours black

Wheel centre/rim:

Pressed steel rim, zinc-plated, blue-passivated, Cr6-free.

Wheel centre colour: blue passivated



Rolling resistance

■ ■ □ □ □ Satisfactory

Operating noise

■ ■ ■ ■ □ Very good







 

 


Floor surface preservation

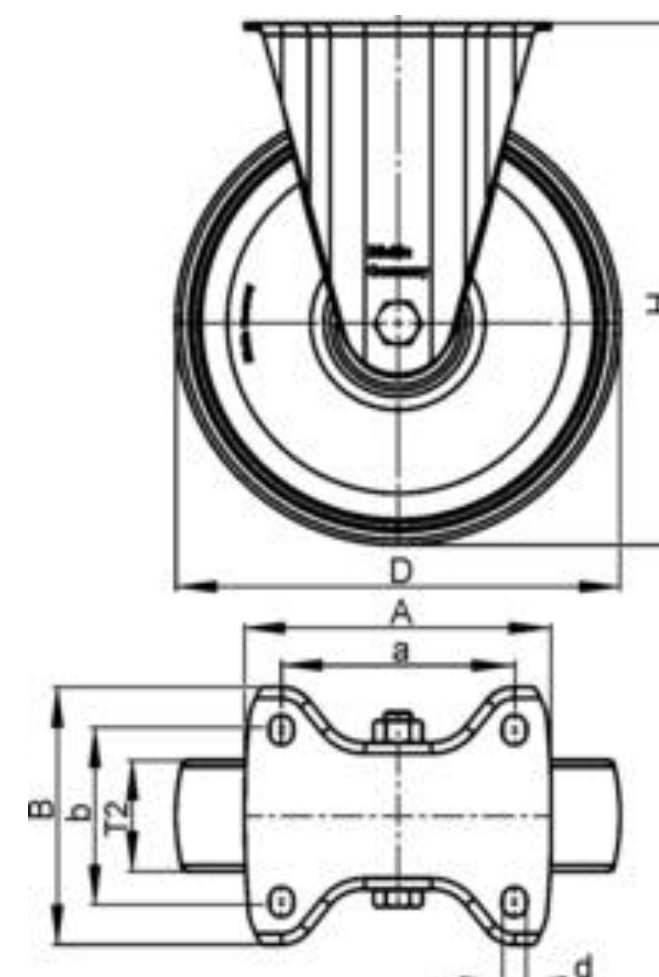
■ ■ ■ ■ □ Very good

Product Data Sheet



Technical data

Plate size		100 x 85
Bolt hole spacing		80 x 60
Bolt hole Ø		9
Wheel Ø		125 mm (D)
Wheel width		37,5 mm (T2)
Load capacity		100 kg
Total height		150 mm (H)
unit weight		1 kg
Temperature resistance		-25 ° C
Temperature resistance to		80 ° C
tread and tyre hardness		80° Shore A
Bearing type:		Roller bearing



Product Data Sheet



Variants



B-VE 125R-EL

Pressed steel fixed castor with top plate fitting, Wheel with standard solid rubber tyres, with pressed steel rim



B-VE 125R-EL-FA

Pressed steel fixed castor with top plate fitting, Wheel with standard solid rubber tyres, with pressed steel rim



B-VE 125R-FA

Pressed steel fixed castor with top plate fitting, Wheel with standard solid rubber tyres, with pressed steel rim



B-VE 125R-SG

Pressed steel fixed castor with top plate fitting, Wheel with standard solid rubber tyres, with pressed steel rim



B-VE 125R-SG-FA

Pressed steel fixed castor with top plate fitting, Wheel with standard solid rubber tyres, with pressed steel rim