

EA986HH-3



EAN: 4047526285852

ID: 285858

, Wheel with pneumatic tyres, with pressed steel rim

Bracket:

Made of heavy pressed steel, with double ball bearing in the swivel head, strong central kingpin, swivel head seals. The special Blickle dynamic riveting process of the swivel head results in minimal swivel head play and smooth rolling characteristics with an increased service life achieved by the work hardening of the ball race grooves. Bolted wheel axle. Zinc-plated, blue-passivated, Cr6-free.


Wheels:

Tyre & running tread: Pneumatic tyre with tube, outstandingly high operational comfort, exceptionally high floor preservation, PAH conform acc. to EU directive 2005/69/EC. Tread colour: black

Rim / wheel centre: Made of pressed steel, with tubular steel hub, zinc-plated, blue-passivated, Cr6-free. Tyre mounted on rim.

Variants:

mit Feststeller "stop-top"

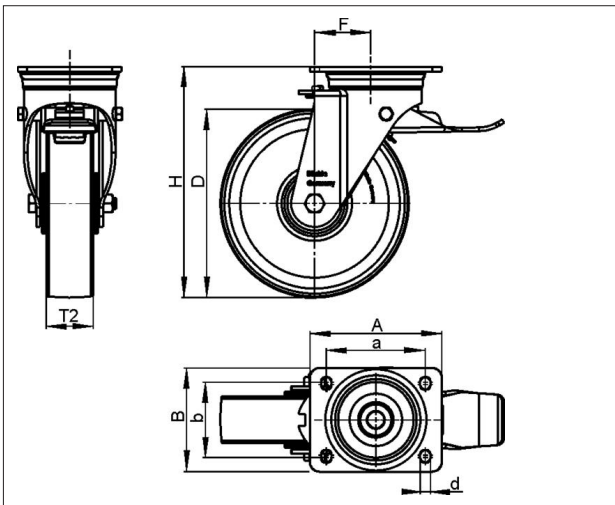

Technical data

Wheel Ø (D)	260 mm
Wheel width (T2)	85 mm
Profile	R01
Load capacity	250 kg
Total height (H)	308 mm
Offset swvl castor (F)	78 mm
Unit weight	6.307 kg
Temperature range from	-25 °C
Temperature range to	50 °C
Tread & tyre hardness	65° Shore A
Bearing type	
Plate size (A,B)	175 x 175 mm
Bolt hole Ø (d)	15 mm
Bolt hole spacing (a,b)	140 x 140 mm

Rolling resistance



Operating noise



Floor surface preservation



Blickle Räder+Rollen GmbH u. Co. KG

Heinrich-Blickle-Straße 1 · 72348 Rosenfeld · Germany

Telefon: +49 7428 932-0 · Telefax: +49 7428 932-209

E-Mail: info@blickle.com · Internet: www.blickle.com

© Blickle Räder+Rollen GmbH u. Co. KG 2013
Rosenfeld · Germany