

EA986HL-100



EAN: 4047526259532

ID: 259531

Pressed steel fixed castor, medium heavy duty brackets, with top plate fitting, Nylon wheel


Bracket:

Made of pressed steel. Bolted wheel axle. Zinc-plated, blue-passivated, Cr6-free.

Wheels:

Tyre & running tread: Made of high-quality, impact-resistant nylon. Tread colour: natural white

Rim / wheel centre: -

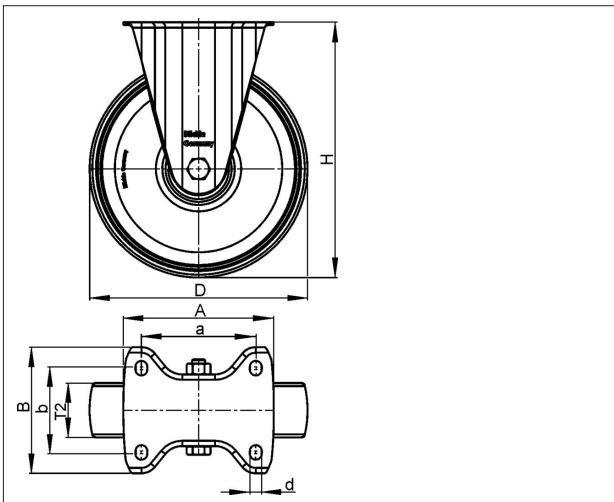

Technical data

Wheel Ø (D)	100 mm
Wheel width (T2)	37 mm
Load capacity	280 kg
Total height (H)	130 mm
Unit weight	0.562 kg
Temperature range from	-25 °C
Temperature range to	80 °C
Tread & tyre hardness	70° Shore D
Bearing type	
Plate size (A,B)	100 x 85 mm
Bolt hole Ø (d)	9 mm
Bolt hole spacing (a,b)	80 x 60 mm

Rolling resistance



Operating noise



Floor surface preservation



BK-PO 100G-1

Variants



With pressed steel
thread guard, zinc-
plated