

Product Data Sheet



LH-PO 200K

EAN 4047526006266

ID 6262

Pressed steel swivel castor, heavy duty castors, with top plate fitting, Nylon wheel

Bracket:

Made of heavy pressed steel, with heavy fork and top plate, very strong bolted and secured central kingpin, double ball bearing in the swivel head, additionally reinforced by the integration of four specially shaped and hardened bearing seats resulting in a very high resistance to shock and impact loads. Bolted wheel axle. Bolted wheel axle. Zinc-plated, blue-passivated, Cr6-free.

Wheels: Made of high-quality, impact-resistant nylon. **Tread colours:**

natural white

Wheel centre/rim: - Wheel centre colour: natural white



Rolling resistance

■■■■■ Excellent

Operating noise

■■□□□ Satisfactory





 
 
 
 
 

 

Floor surface preservation

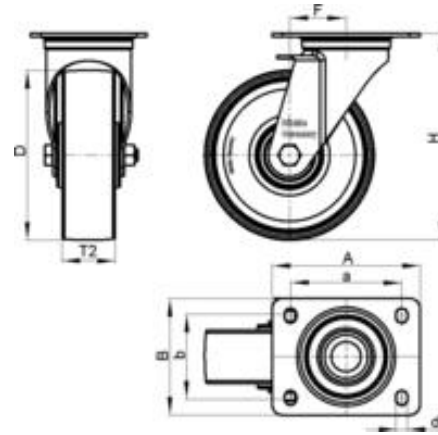
■■□□□ Satisfactory

Product Data Sheet



Technical data

Plate size		140 x 110
Bolt hole spacing		105 x 75-80
Bolt hole Ø		11
Wheel Ø		200 mm (D)
Wheel width		50 mm (T2)
Load capacity		600 kg
Total height		245 mm (H)
Offset swivel castor		70 mm
unit weight		3,6 kg
Temperature resistance		-25 ° C
Temperature resistance to		80 ° C
tread and tyre hardness		70° Shore D
Bearing type		Ball bearing



Product Data Sheet



Variants



LH-PO 200K-CS13

Pressed steel swivel castor, heavy duty castors, with top plate fitting and central brake 'central-stop', Nylon wheel



LH-PO 200K-CS13-FA

Pressed steel swivel castor, heavy duty castors, with top plate fitting and central brake 'central-stop', Nylon wheel



LH-PO 200K-FA

Pressed steel swivel castor, heavy duty castors, with top plate fitting, Nylon wheel



LH-PO 200K-FI

Pressed steel swivel castor, heavy duty castors, with top plate fitting and 'stop-fix' brake, Nylon wheel



LH-PO 200K-FI-FA

Pressed steel swivel castor, heavy duty castors, with top plate fitting and 'stop-fix' brake, Nylon wheel



LH-PO 200K-IS

Pressed steel swivel castor, heavy duty castors, with top plate fitting and 'ideal-stop' brake, Nylon wheel



LH-PO 200K-IS-FA

Pressed steel swivel castor, heavy duty castors, with top plate fitting and 'ideal-stop' brake, Nylon wheel



LH-PO 200K-ST

Pressed steel swivel castor, heavy duty castors, with top plate fitting and 'stop-top' brake, Nylon wheel



LH-PO 200K-ST-FA

Pressed steel swivel castor, heavy duty castors, with top plate fitting and 'stop-top' brake, Nylon wheel

Product Data Sheet



Option:



RI-05.03

Directional lock