

# Product Data Sheet



## BK-VSTH 65K

**EAN** 4047526119249

**ID** 760729

**Pressed steel compact fixed castor with top plate fitting, Heavy duty wheel with Blickle Extrathane® polyurethane tread, with steel wheel centre**

### Bracket:

Made of pressed steel. Bolted wheel axle. Zinc-plated, blue-passivated, Cr6-free.

### Wheels:

Made of high-quality, reaction-injected polyurethane-elastomer Blickle Extrathane®, low-noise operation, low rolling resistance, good floor preservation, very high abrasion resistance, high cut and tear propagation resistance, very good chemical connection with the wheel centre.


### Tread/tyre:

Made of high-quality polyurethane-elastomer Blickle Extrathane®.

**Tread colours:** light brown

**Wheel centre/rim:** Made of steel. Casted tread.

**Wheel centre colour:** silver

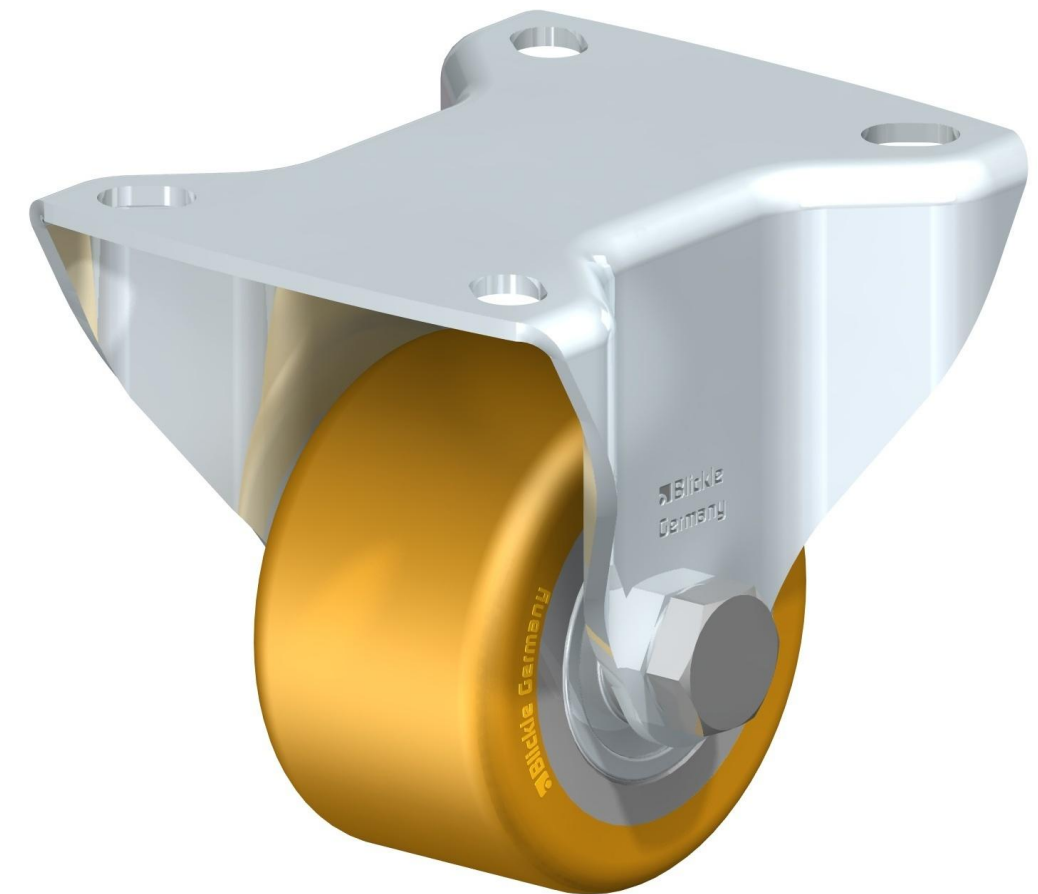

### Rolling resistance

■ ■ ■ ■ □ Very good

### Operating noise

■ ■ ■ □ □ Good






 
 




### Floor surface preservation

■ ■ ■ □ □ Good

# Product Data Sheet



## Technical data

Plate size		100 x 85
Bolt hole spacing		80 x 60
Bolt hole Ø		9
Wheel Ø		65 mm (D)
Wheel width		40 mm (T2)
Load capacity		250 kg
Total height		90 mm (H)
unit weight		0,8 kg
Temperature resistance		-25 ° C
Temperature resistance to		70 ° C
tread and tyre hardness		92° Shore A
Bearing type		Ball bearing

