

## EA986HV-75



**EAN: 4047526275280**

**ID: 275289**

**Light duty fixed castor with top plate fitting, Nylon wheel**


**Bracket:**

Made of pressed steel. Bolted wheel axle. Zinc-plated, blue-passivated, Cr6-free.

**Wheels:**

**Tyre & running tread:** Made of high-quality, impact-resistant nylon, very low rolling and swivelling resistance, smooth running performance on even floors, very high abrasion resistance. Tread colour: black

**Rim / wheel centre:** -

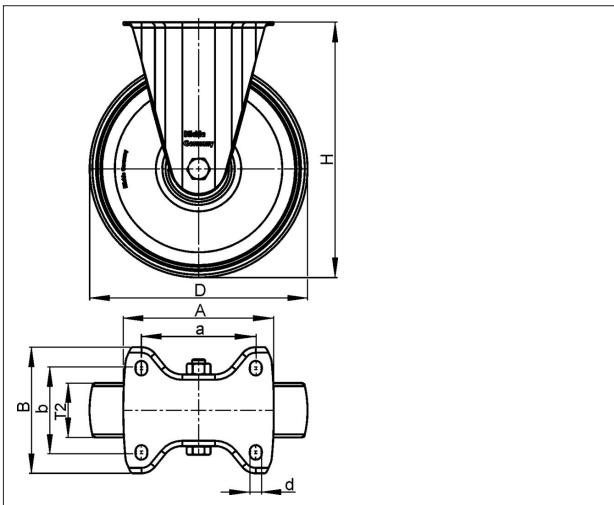

### Technical data

|                         |                |
|-------------------------|----------------|
| Wheel Ø (D)             | 75 mm          |
| Wheel width (T2)        | 23 mm          |
| Load capacity           | 75 kg          |
| Total height (H)        | 100 mm         |
| Unit weight             | 0.188 kg       |
| Temperature range from  | -25 °C         |
| Temperature range to    | 80 °C          |
| Tread & tyre hardness   | 70° Shore D    |
| Bearing type            |                |
| Plate size (A,B)        | 60 x 60 mm     |
| Bolt hole Ø (d)         | 6,2 mm         |
| Bolt hole spacing (a,b) | 38x38/48x48 mm |

Rolling resistance



Operating noise



Floor surface preservation

