

## EA986HW-2



**EAN: 4047526273194**

**ID: 273193**

**Light duty swivel castor with top plate fitting with synthetic brake lever, Nylon wheel**

**Bracket:**

Made of pressed steel, with double ball bearing in the swivel head, ball protection by the special top plate and ball disc design. The special Blickle dynamic riveting process of the swivel head results in minimal swivel head play and smooth rolling characteristics with an increased service life achieved by the work hardening of the ball race grooves. Bolted wheel axle. Zinc-plated, blue-passivated, Cr6-free.


**Wheels:**

**Tyre & running tread:** Made of high-quality, impact-resistant nylon, very low rolling and swivelling resistance, smooth running performance on even floors, very high abrasion resistance. Tread colour: black

**Rim / wheel centre:** -

**Variants:**

mit Feststeller "stop-fix"

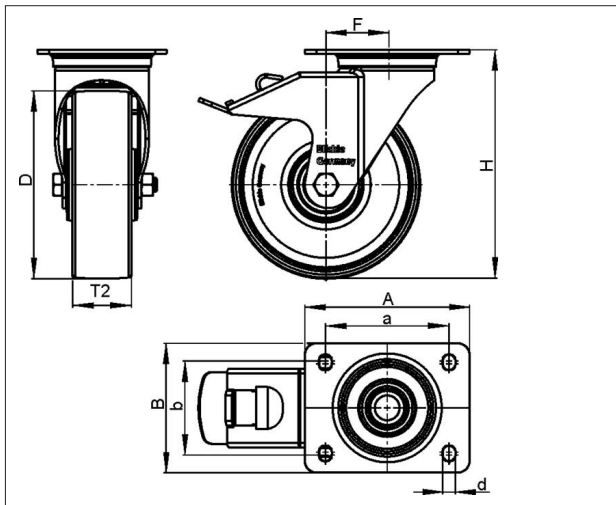

### Technical data

|                         |                |
|-------------------------|----------------|
| Wheel Ø (D)             | 75 mm          |
| Wheel width (T2)        | 23 mm          |
| Load capacity           | 75 kg          |
| Total height (H)        | 100 mm         |
| Offset swvl castor (F)  | 29 mm          |
| Unit weight             | 0.269 kg       |
| Temperature range from  | -25 °C         |
| Temperature range to    | 80 °C          |
| Tread & tyre hardness   | 70° Shore D    |
| Bearing type            |                |
| Plate size (A,B)        | 60 x 60 mm     |
| Bolt hole Ø (d)         | 6,2 mm         |
| Bolt hole spacing (a,b) | 38x38/48x48 mm |

Rolling resistance



Operating noise



Floor surface preservation

