

EA986HX-160



EAN: 4047526043155

ID: 43158

Pressed steel fixed castor, medium duty brackets, with top plate fitting, Heavy duty wheel with elastic solid rubber tyres 'Blickle EasyRoll', with nylon wheel centre


Bracket:

Made of pressed steel. Bolted wheel axle. Zinc-plated, blue-passivated, Cr6-free.

Wheels:

Tyre & running tread: Made of high-quality elastic solid rubber, in smooth rolling quality "Blickle EasyRoll", very high operational comfort, low-noise operation, low rolling resistance, very good floor preservation, vulcanised on the wheel centre. Tread colour: black

Rim / wheel centre: Made of high-quality, impact-resistant nylon. Vulcanised tyre.

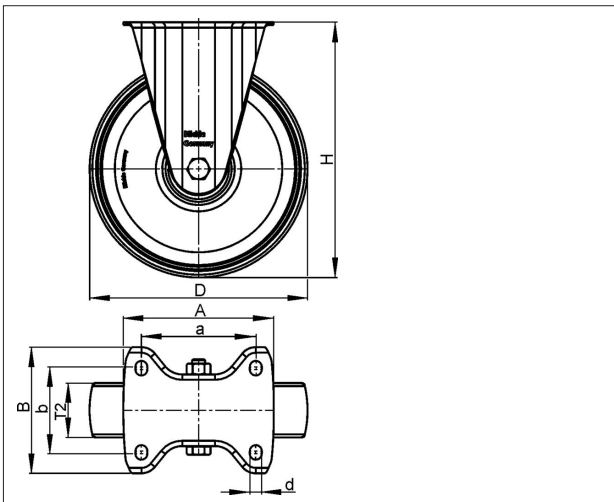

Technical data

Wheel Ø (D)	160 mm
Wheel width (T2)	50 mm
Load capacity	400 kg
Total height (H)	195 mm
Unit weight	1.562 kg
Temperature range from	-25 °C
Temperature range to	80 °C
Tread & tyre hardness	65° Shore A
Bearing type	
Plate size (A,B)	140 x 110 mm
Bolt hole Ø (d)	11 mm
Bolt hole spacing (a,b)	105 x 75-80 mm

Rolling resistance



Operating noise



Floor surface preservation



B-POEV 160R

Variants	
	With pressed steel thread guard, zinc-plated
	With non-marking blue tyre
	With non-marking grey tyre
	With stainless steel roller bearing in the wheel hub