

## EA986HX-80



**EAN: 4047526605902**

**ID: 605907**

**Pressed steel fixed castor, medium duty brackets, with top plate fitting, Heavy duty wheel with elastic solid rubber tyres 'Blickle EasyRoll', with nylon wheel centre**


**Bracket:**

Made of pressed steel. Bolted wheel axle. Zinc-plated, blue-passivated, Cr6-free.

**Wheels:**

**Tyre & running tread:** Made of high-quality elastic solid rubber, in smooth rolling quality "Blickle EasyRoll", very high operational comfort, low-noise operation, low rolling resistance, very good floor preservation, vulcanised on the wheel centre. Tread colour: black

**Rim / wheel centre:** Made of high-quality, impact-resistant nylon. Vulcanised tyre.

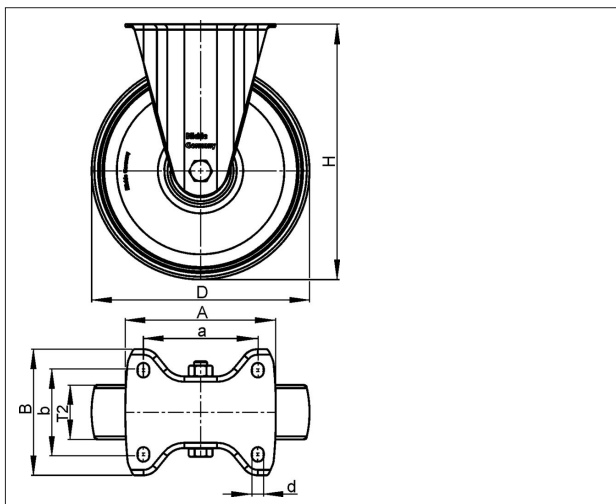

### Technical data

Wheel Ø (D)	80 mm
Wheel width (T2)	32 mm
Load capacity	140 kg
Total height (H)	102 mm
Unit weight	0.406 kg
Temperature range from	-25 °C
Temperature range to	80 °C
Tread & tyre hardness	65° Shore A
Bearing type	
Plate size (A,B)	100 x 85 mm
Bolt hole Ø (d)	9 mm
Bolt hole spacing (a,b)	80 x 60 mm

Rolling resistance







Operating noise



Floor surface preservation



## B-POEV 80R

Variants	
	With pressed steel thread guard, zinc-plated
	With non-marking blue tyre
	With non-marking grey tyre
	With stainless steel roller bearing in the wheel hub