

## EA986JB-200



EAN: 4047526020712

ID: 20719

**Pressed steel swivel castor, medium heavy duty brackets, with top plate fitting, Wheel with standard solid rubber tyres, with synthetic rim**


**Bracket:**

Made of heavy pressed steel, with double ball bearing in the swivel head, strong central kingpin, swivel head seals. The special Blickle dynamic riveting process of the swivel head results in minimal swivel head play and smooth rolling characteristics with an increased service life achieved by the work hardening of the ball race grooves. Bolted wheel axle. Zinc-plated, blue-passivated, Cr6-free.

**Wheels:**

**Tyre & running tread:** Made of standard solid rubber, very high operational comfort, low-noise operation, very good floor preservation, PAH conform acc. to EU directive 2005/69/EC. Tread colour: black

**Rim / wheel centre:** Made of high-quality, impact-resistant polypropylene. Pressed-on tyre.

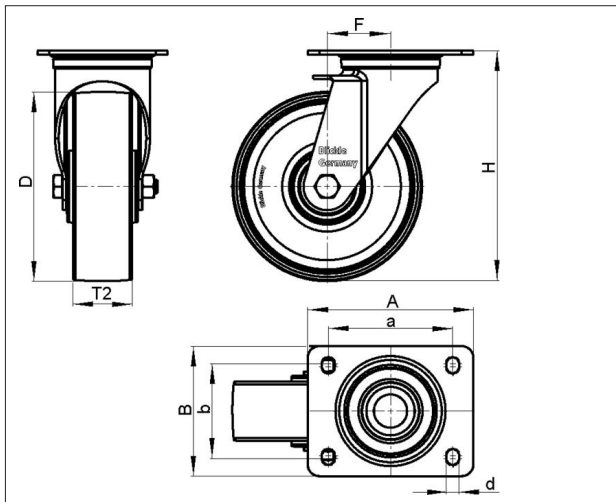

### Technical data

|                         |                |
|-------------------------|----------------|
| Wheel Ø (D)             | 200 mm         |
| Wheel width (T2)        | 50 mm          |
| Load capacity           | 205 kg         |
| Total height (H)        | 235 mm         |
| Offset swvl castor (F)  | 65 mm          |
| Unit weight             | 2.861 kg       |
| Temperature range from  | -20 °C         |
| Temperature range to    | 60 °C          |
| Tread & tyre hardness   | 80° Shore A    |
| Bearing type            |                |
| Plate size (A,B)        | 140 x 110 mm   |
| Bolt hole Ø (d)         | 11 mm          |
| Bolt hole spacing (a,b) | 105 x 75-80 mm |

Rolling resistance



Operating noise



Floor surface preservation



**L-VPP 200R**

| Variants                                                                           |                                              |
|------------------------------------------------------------------------------------|----------------------------------------------|
|   | With pressed steel thread guard, zinc-plated |
|   | With non-marking grey tyre                   |
|  | With 'stop-top' brake                        |