

EA986JF-100



EAN: 4047526624804

ID: 624809

**, Heavy duty wheel with elastic solid rubber tyres
'Blickle EasyRoll', with aluminium wheel centre**

Bracket:

Made of heavy pressed steel, swivel bracket with double ball bearing in the swivel head, swivel head seals. The special Blickle dynamic riveting process of the swivel head results in minimal swivel head play and smooth rolling characteristics with an increased service life achieved by the work hardening of the ball race grooves. Bolted wheel axle. Zinc-plated, blue-passivated, Cr6-free.


Wheels:

Tyre & running tread: Made of high-quality elastic solid rubber, in smooth rolling quality "Blickle EasyRoll", very high operational comfort, low-noise operation, low rolling resistance, very good floor preservation, vulcanised on the wheel centre. Tread colour: black

Rim / wheel centre: Made of die-cast aluminium. Vulcanised tyre.

Variants:

mit Feststeller "stop-top"

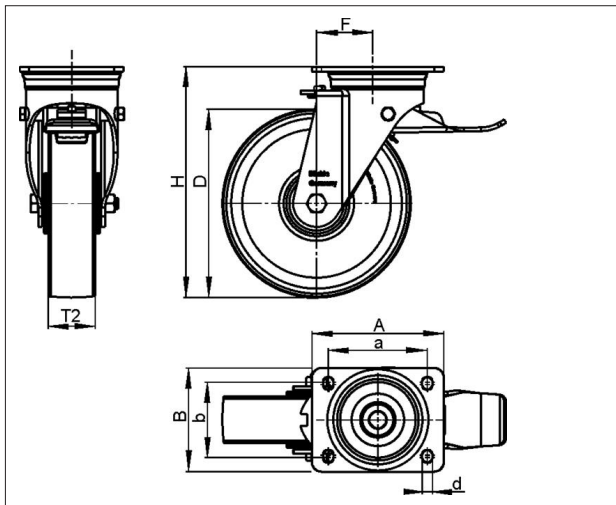

Technical data

Wheel Ø (D)	100 mm
Wheel width (T2)	40 mm
Load capacity	200 kg
Total height (H)	130 mm
Offset swvl castor (F)	45 mm
Unit weight	1.464 kg
Temperature range from	-25 °C
Temperature range to	80 °C
Tread & tyre hardness	65° Shore A
Bearing type	
Plate size (A,B)	100 x 85 mm
Bolt hole Ø (d)	9 mm
Bolt hole spacing (a,b)	80 x 60 mm

Rolling resistance



Operating noise



Floor surface preservation



Blickle Räder+Rollen GmbH u. Co. KG

Heinrich-Blickle-Straße 1 · 72348 Rosenfeld · Germany

Telefon: +49 7428 932-0 · Telefax: +49 7428 932-209

E-Mail: info@blickle.com · Internet: www.blickle.com

© Blickle Räder+Rollen GmbH u. Co. KG 2013
Rosenfeld · Germany

LK-ALEV 100K-1-ST

Variants	
	With central braking system 'central-stop'
	Antistatic version
	With non-marking grey tyre
	With 'stop-top' brake