

## EA986JF-160



EAN: 4047526263928

ID: 263921

, Heavy duty wheel with elastic solid rubber tyres  
'Blickle EasyRoll', with aluminium wheel centre

**Bracket:**

Made of heavy pressed steel, with double ball bearing in the swivel head, strong central kingpin, swivel head seals. The special Blickle dynamic riveting process of the swivel head results in minimal swivel head play and smooth rolling characteristics with an increased service life achieved by the work hardening of the ball race grooves. Bolted wheel axle. Zinc-plated, blue-passivated, Cr6-free.


**Wheels:**

**Tyre & running tread:** Made of high-quality elastic solid rubber, in smooth rolling quality "Blickle EasyRoll", very high operational comfort, low-noise operation, low rolling resistance, very good floor preservation, vulcanised on the wheel centre. Tread colour: black

**Rim / wheel centre:** Made of die-cast aluminium. Vulcanised tyre.

**Variants:**

mit Feststeller "stop-top"

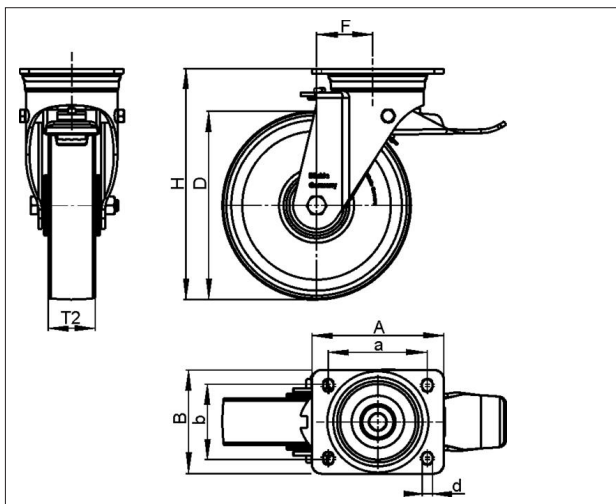

## Technical data

|                         |                |
|-------------------------|----------------|
| Wheel Ø (D)             | 160 mm         |
| Wheel width (T2)        | 50 mm          |
| Load capacity           | 400 kg         |
| Total height (H)        | 202 mm         |
| Offset swvl castor (F)  | 63 mm          |
| Unit weight             | 3.685 kg       |
| Temperature range from  | -25 °C         |
| Temperature range to    | 80 °C          |
| Tread & tyre hardness   | 65° Shore A    |
| Bearing type            |                |
| Plate size (A,B)        | 140 x 110 mm   |
| Bolt hole Ø (d)         | 11 mm          |
| Bolt hole spacing (a,b) | 105 x 75-80 mm |

Rolling resistance



Operating noise



Floor surface preservation



Blickle Räder+Rollen GmbH u. Co. KG

Heinrich-Blickle-Straße 1 · 72348 Rosenfeld · Germany

Telefon: +49 7428 932-0 · Telefax: +49 7428 932-209

E-Mail: info@blickle.com · Internet: www.blickle.com

© Blickle Räder+Rollen GmbH u. Co. KG 2013  
Rosenfeld · Germany

**LK-ALEV 160K-ST**

| Variants                                                                           |                            |
|------------------------------------------------------------------------------------|----------------------------|
|   | With 'ideal-stop' brake    |
|   | With non-marking grey tyre |
|  | With 'stop-top' brake      |