

EA986JX-125



EAN: 4047526690410

ID: 690412

Pressed steel extra heavy duty twin wheel swivel castor, with top plate fitting, Heavy duty wheel with elastic solid rubber tyres 'Blickle EasyRoll', with aluminium wheel centre


Bracket:

Made of heavy pressed steel, with heavy fork and top plate, very strong bolted and secured central kingpin, double ball bearing in the swivel head, additionally reinforced by the integration of four specially shaped and hardened bearing seats resulting in a very high resistance to shock and impact loads.

Wheels:

Tyre & running tread: Made of high-quality elastic solid rubber, in smooth rolling quality "Blickle EasyRoll", very high operational comfort, low-noise operation, low rolling resistance, very good floor preservation, vulcanised on the wheel centre. Tread colour: black

Rim / wheel centre: Made of die-cast aluminium. Vulcanised tyre.

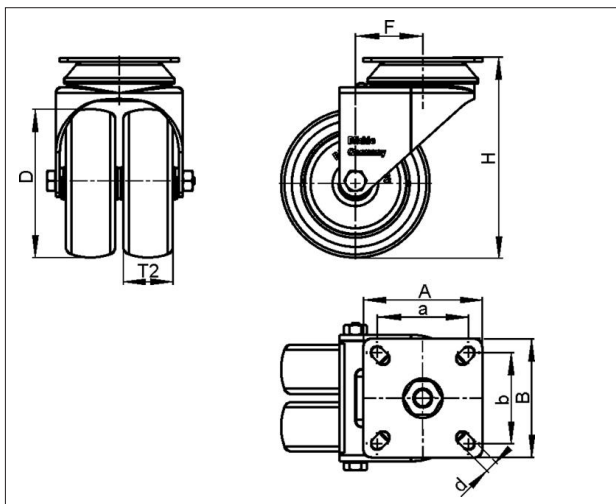

Technical data

Wheel Ø (D)	125 mm
Wheel width (T2)	2 x 40 mm
Load capacity	500 kg
Total height (H)	170 mm
Offset swvl castor (F)	50 mm
Unit weight	3.6 kg
Temperature range from	-25 °C
Temperature range to	80 °C
Tread & tyre hardness	65° Shore A
Bearing type	
Plate size (A,B)	110 x 140 mm
Bolt hole Ø (d)	11 mm
Bolt hole spacing (a,b)	75-80 x 105 mm

Rolling resistance



Operating noise



Floor surface preservation



LHD-ALEV 125K

Variants



Antistatic version



With non-marking grey
tyre