

Product Data Sheet



BH-ALBS 150K

EAN 4047526076092

ID 754030

Pressed steel fixed castor, heavy duty brackets, with top plate fitting, Heavy duty wheel with Blickle Besthane® Soft polyurethane tread, with aluminium wheel centre

Bracket:

Made of pressed steel. Bolted wheel axle. Zinc-plated, blue-passivated, Cr6-free.

Wheels:

Made of high-quality, reaction-injected polyurethane-elastomer Blickle Besthane® Soft, very high operational comfort through the especially thick, elastic tread, low-noise operation, very low rolling resistance, high dynamic load capacity, very good floor preservation, very high abrasion resistance, high cut and tear propagation resistance, very good chemical connection with the wheel centre.

Tread/tyre:


Made of high-quality polyurethane-elastomer Blickle Besthane® Soft, very low rolling resistance, high dynamic load capacity.

Tread colours blue

Wheel centre/rim:

Made of die-cast aluminium. Casted tread.

Wheel centre colour: silver grey

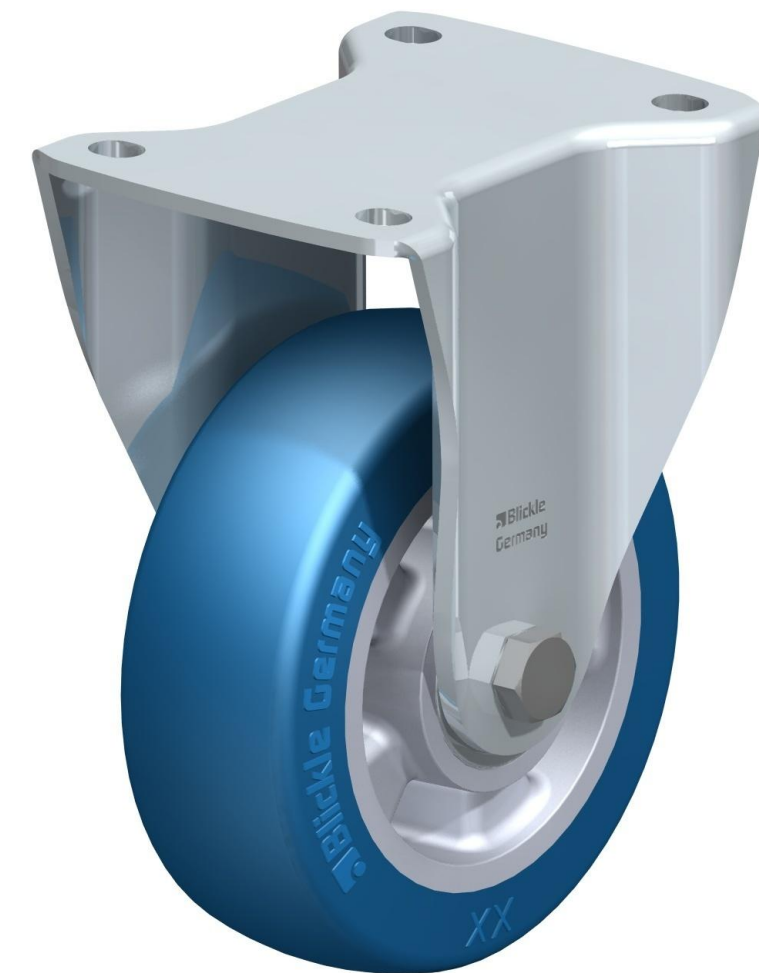

Rolling resistance

■■■■■ Excellent

Operating noise

■■■■□ Very good


 

 
 

Floor surface preservation

■■■■□ Very good

Product Data Sheet



Technical data

Plate size		140 x 110
Bolt hole spacing		105 x 75-80
Bolt hole Ø		11
Wheel Ø		150 mm (D)
Wheel width		54 mm (T2)
Load capacity		500 kg
Total height		197 mm (H)
unit weight		2,5 kg
Temperature resistance		-25 ° C
Temperature resistance to		70 ° C
tread and tyre hardness		75° Shore A
Bearing type:		Ball bearing

