


Series: LK-ALBS, BK-ALBS, BH-ALBS



Pressed steel castors, medium heavy duty brackets, with top plate fitting, wheel with Blickle Besthane® Soft polyurethane tread

230 - 600 kg

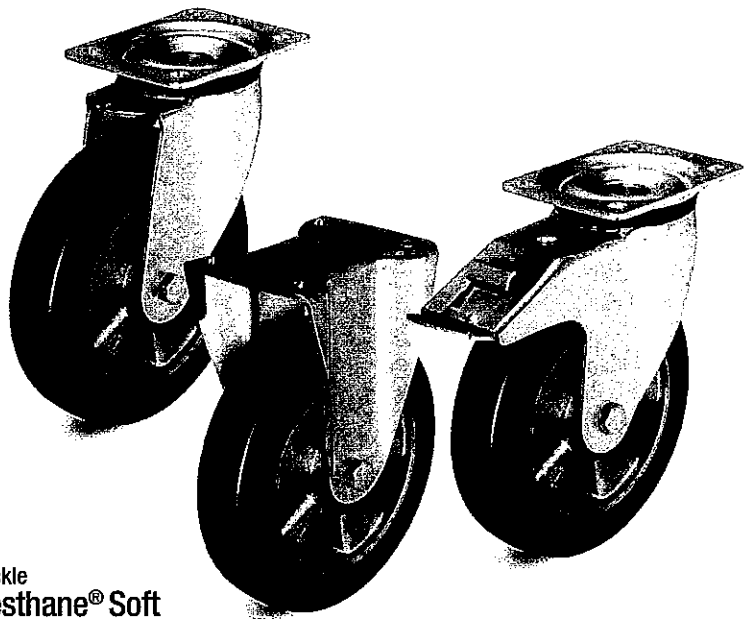

Brackets: LK/BK/BH series - Made of heavy pressed steel, swivel bracket with double ball bearing in the swivel head, strong central kingpin (wheel Ø 125x54 - 200 mm), swivel head seals. The special Blickle dynamic riveting process of the swivel head results in minimal swivel head play and smooth rolling characteristics with an increased service life achieved by the work hardening of the ball race grooves. Bolted wheel axle. Zinc-plated, blue-passivated, Cr6-free. Bracket overview: Page 66 Top plate drawings: Page 77 Wheel and swivel head 'stop-fix' brake: Page 80


Wheels: ALBS series - Tread: Made of high-quality polyurethane-elastomer Blickle Besthane® Soft, 75° shore A, very low rolling resistance, high dynamic load capacity, blue, non-marking, non-staining. Wheel centre: Made of die-cast aluminium. Bearing type: Two pressed-in ball bearings. Detailed description: Page 238 and 47

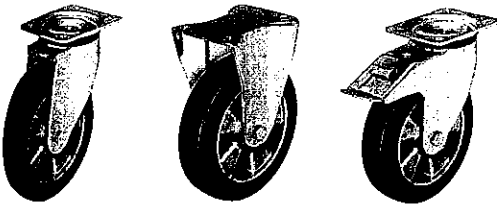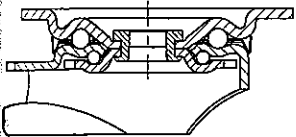

Swivel castors	Fixed castors	Swivel castors with 'stop-fix' brake	Wheel Ø [mm]	Wheel width [mm]	Load capacity [kg]	Bearing type	Total height [mm]	Plate size [mm]	Bolt hole spacing [mm]	Bolt hole Ø [mm]	Offset swivel castor [mm]
LK-ALBS 82K	BK-ALBS 82K	LK-ALBS 82K-FI	80	40	230	Ball bearing	110	100 x 85	80 x 60	9	40
LK-ALBS 100K-1	BK-ALBS 100K-1	LK-ALBS 100K-1-FI	100	40	300	Ball bearing	130	100 x 85	80 x 60	9	45
LK-ALBS 100K-3	BK-ALBS 100K-3	LK-ALBS 100K-3-FI	100	40	300	Ball bearing	130	140 x 110	105 x 75-80	11	45
LK-ALBS 125K-1	BK-ALBS 125K-1	LK-ALBS 125K-1-FI	125	40	350	Ball bearing	155	100 x 85	80 x 60	9	48
LK-ALBS 125K-3	BK-ALBS 125K-3	LK-ALBS 125K-3-FI	125	40	350	Ball bearing	155	140 x 110	105 x 75-80	11	48
LK-ALBS 127K	BH-ALBS 127K	LK-ALBS 127K-FI	125	54	450	Ball bearing	170	140 x 110	105 x 75-80	11	55
LK-ALBS 150K	BH-ALBS 150K	LK-ALBS 150K-FI	150	54	500	Ball bearing	197	140 x 110	105 x 75-80	11	63
LK-ALBS 160K	BH-ALBS 160K	LK-ALBS 160K-FI	160	50	550	Ball bearing	202	140 x 110	105 x 75-80	11	63
LK-ALBS 180K	BH-ALBS 180K	LK-ALBS 180K-FI	180	50	600	Ball bearing	223	140 x 110	105 x 75-80	11	65
LK-ALBS 200K	BH-ALBS 200K	LK-ALBS 200K-FI	200	50	600	Ball bearing	245	140 x 110	105 x 75-80	11	65

EA986KA-4

Options

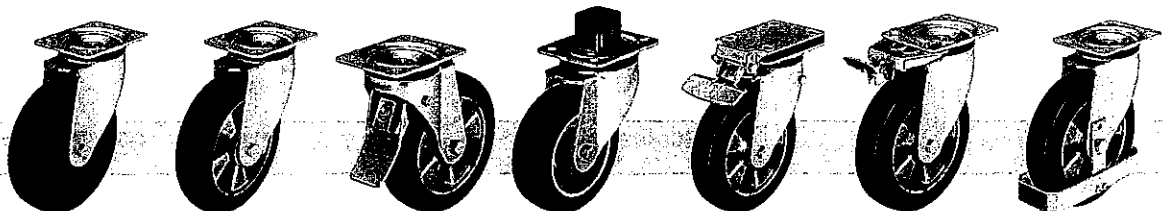

With hydrolysis resistant wheel With extra crowned running tread With 'stop-top' brake With central braking system 'central-stop' With 'ideal-stop' brake ttt. height +17mm * Directional lock (retro-fit) 1 x 360° With steel foot guard

Technical description page	39	80	81	80	83	84
Product code suffix	POBS series	-CO	-ST	-CS11	-IS	refer to **
Available for	upon request	upon request	all sizes	wheel Ø 100 - 125x40 mm	Ø 100, 125, 160, 200 with plate 140x110	for wheel Ø and plate dimensions refer to **

* Matching synthetic adapter plate for total height compensation for swivel and fixed castors without 'ideal-stop' brake: Product code AP3
 ** RI-05.01 available for wheel Ø 80 - 125 mm with plate 100x85 mm, RI-03.03 available for wheel Ø 100 - 125x40 mm with plate 140x110 mm, RI-05.03 available for wheel Ø 125x54 - 200 mm (only for swivel castors without brake)