

## EA986KK-200



**EAN: 4047526299910**

**ID: 299917**

**, Heavy duty wheel with Blickle Extrathane® polyurethane tread, with aluminium wheel centre**

**Bracket:**

Sturdy welded steel construction, with double ball bearing in the swivel head, additionally reinforced by the integration of four specially shaped and hardened bearing seats, swivel head seal with labyrinth design, fitted grease nipple, bolted and secured with a welded very strong central kingpin. Bolted wheel axle. Zinc-plated, blue-passivated, Cr6-free.


**Wheels:**

**Tyre & running tread:** Made of high-quality, reaction-injected polyurethane-elastomer Blickle Extrathane®, low-noise operation, low rolling resistance, good floor preservation, very high abrasion resistance, high cut and tear propagation resistance, very good chemical connection with the wheel centre. Tread colour: light brown

**Rim / wheel centre:** Made of die-cast aluminium. Casted tread.

**Variants:**

mit Feststeller "stop-top"

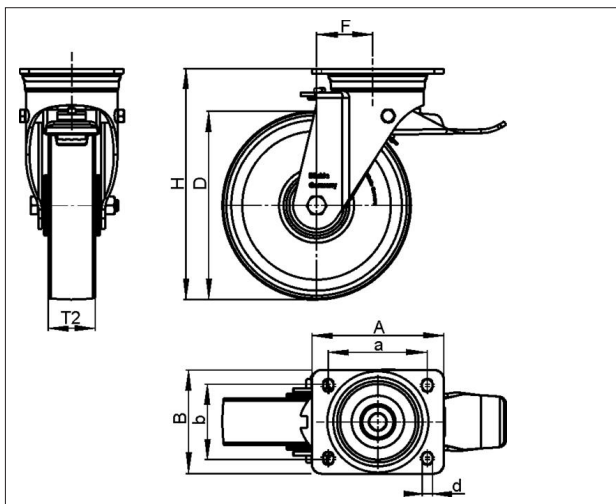

### Technical data

|                          |                |
|--------------------------|----------------|
| Wheel Ø (D)              | 200 mm         |
| Wheel width (T2)         | 50 mm          |
| Load capacity            | 800 kg         |
| Total height (H)         | 245 mm         |
| Offset swivel castor (F) | 60 mm          |
| Unit weight              | 5.018 kg       |
| Temperature range from   | -25 °C         |
| Temperature range to     | 70 °C          |
| Tread & tyre hardness    | 92° Shore A    |
| Bearing type             |                |
| Plate size (A,B)         | 140 x 110 mm   |
| Bolt hole Ø (d)          | 11 mm          |
| Bolt hole spacing (a,b)  | 105 x 75-80 mm |

Rolling resistance



Operating noise



Floor surface preservation

