

Product Data Sheet



LSD-GTH 252K

EAN 4047526290078

ID 290072

Welded steel heavy duty twin wheel swivel castor, strong swivel head design, Heavy duty wheel with Blickle Extrathane® polyurethane tread, with cast iron wheel centre

Bracket:

Particularly rugged welded steel construction, with axial grooved ball bearing DIN 711 and tapered roller bearing DIN 720 in the swivel head, dust and splash-proof, fitted grease nipple, bolted and secured with a welded very strong central kingpin. Bolted wheel axle. Zinc-plated, yellow-passivated, Cr6-free.


Wheels:

Made of high-quality, reaction-injected polyurethane-elastomer Blickle Extrathane®, low-noise operation, low rolling resistance, good floor preservation, very high abrasion resistance, high cut and tear propagation resistance, very good chemical connection with the wheel centre.

Tread colours: light brown

Wheel centre/rim: Made of grey cast iron, lacquered. Casted tread.

Wheel centre colour: silver

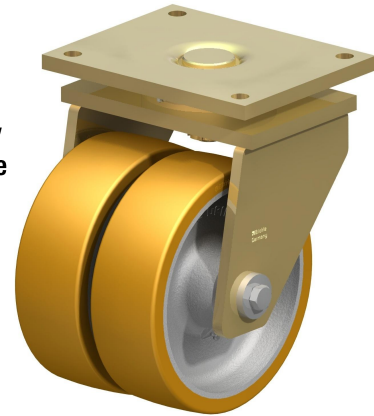

Rolling resistance

■■■■□ Very good

Operating noise

■■■■□ Good

Floor surface preservation

■■■■□ Good

Product Data Sheet



Technical data

Plate size		200 x 255
Bolt hole spacing		160 x 210
Bolt hole Ø		18
Wheel Ø		250 mm (D)
Wheel width		2 x 80 mm (T2)
Load capacity		3200 kg
Total height		330 mm (H)
Offset swivel castor		70 mm
unit weight		38,4 kg
Temperature resistance		-25 ° C
Temperature resistance to		70 ° C
tread and tyre hardness		92° Shore A
Bearing type		Ball bearing

