

# Product Data Sheet



## LSD-GSP0 80K

EAN 4047526614539

ID 614537

**Welded steel extra heavy duty twin wheel swivel castors, extra strong swivel head design, Heavy duty wheels made of cast nylon**

### Bracket:

Particularly rugged welded steel construction, with axial grooved ball bearing DIN 711 and tapered roller bearing DIN 720 in the swivel head, dust and splash-proof, fitted grease nipple, bolted and secured with a welded very strong central kingpin. Bolted wheel axle  
Lacquered, red.

### Wheels:


Made of high-quality, impact-resistant, hard and tough, highly compressed cast nylon with outstanding load capacity, very low rolling and swivelling resistance, smooth running performance on even floors, very high abrasion resistance.

**Tread/tyre:** Made of high-quality, impact-resistant cast nylon.

**Tread colours:** natural beige

**Wheel centre/rim:** -

**Wheel centre colour:** natural beige

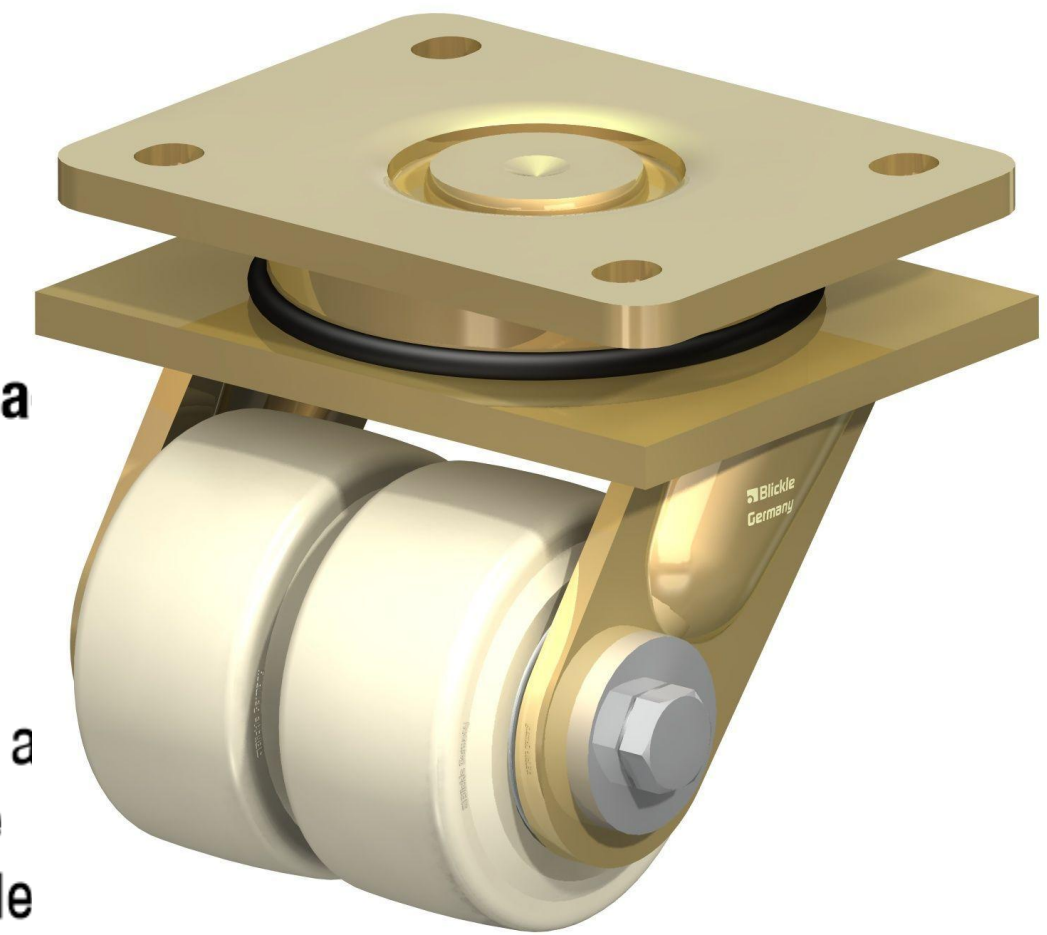

### Rolling resistance

■■■■■ Excellent

### Operating noise

■■□□□ Satisfactory











### Floor surface preservation

■■□□□ Satisfactory

# Product Data Sheet



## Technical data

Plate size		110 x 140
Bolt hole spacing		75-80 x 105
Bolt hole Ø		11
Wheel Ø		80 mm (D)
Wheel width		2 x 40 mm (T2)
Load capacity		1750 kg
Total height		125 mm (H)
Offset swivel castor		40 mm
unit weight		4,2 kg
Temperature resistance		-25 ° C
Temperature resistance to		80 ° C
tread and tyre hardness		80° Shore D
Bearing type:		Ball bearing

