

## EA986KX-250



**EAN: 4047526309480**

**ID: 309484**

**Welded steel heavy duty fixed castor, Heavy duty wheels made of cast nylon**


**Bracket:**

Particularly rugged welded steel construction. Bolted wheel axle. Zinc-plated, yellow-passivated, Cr6-free.

**Wheels:**

**Tyre & running tread:** Made of high-quality, impact-resistant, hard and tough, highly compressed cast nylon with outstanding load capacity, very low rolling and swivelling resistance, smooth running performance on even floors, very high abrasion resistance. Tread colour: natural beige

**Rim / wheel centre:** -

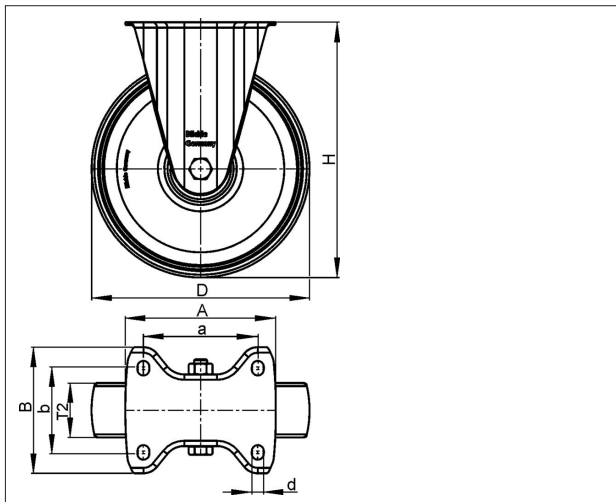

### Technical data

|                         |              |
|-------------------------|--------------|
| Wheel Ø (D)             | 250 mm       |
| Wheel width (T2)        | 80 mm        |
| Load capacity           | 6000 kg      |
| Total height (H)        | 330 mm       |
| Unit weight             | 18.967 kg    |
| Temperature range from  | -25 °C       |
| Temperature range to    | 80 °C        |
| Tread & tyre hardness   | 80° Shore D  |
| Bearing type            |              |
| Plate size (A,B)        | 255 x 200 mm |
| Bolt hole Ø (d)         | 18 mm        |
| Bolt hole spacing (a,b) | 210 x 160 mm |

Rolling resistance



Operating noise



Floor surface preservation

