


BKX-POTH 75G

EAN: 4047526084387

ID: 754137

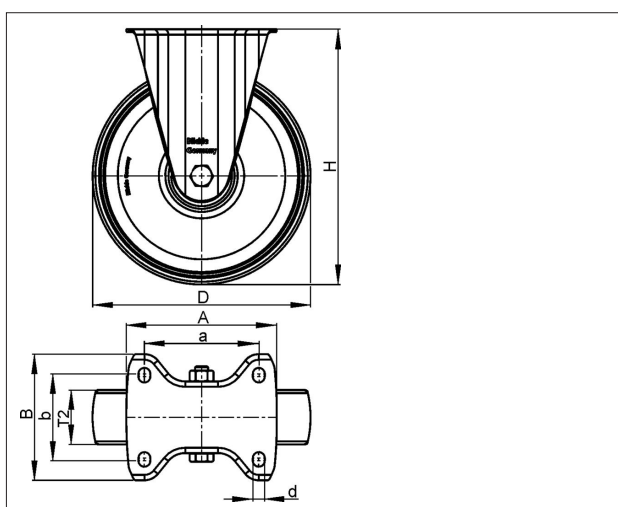

Technical data

Wheel Ø (D)	75 mm
Wheel width (T2)	37 mm
Load capacity	200 kg
Total height (H)	108 mm
Unit weight	0.557 kg
Temperature range from	-25 °C
Temperature range to	70 °C
Tread & tyre hardness	94° Shore A
Bearing type	Plain bore
Plate size (A,B)	100 x 85 mm
Bolt hole Ø (d)	9 mm
Bolt hole spacing (a,b)	80 x 60 mm

Rolling resistance



Operating noise



Floor surface preservation

