

EA986LJ-150



EAN: 4047526270049

ID: 270041

Heat-resistant pressed stainless steel fixed castor with top plate fitting, Heat-resistant Blickle TempLine® Classic thermoset wheel


Bracket:

Made of pressed high-quality, chromium-nickel stainless steel (Material No. 1.4301/AISI 304). All parts incl. axle material are corrosion-resistant. Bolted wheel axle. Vibration-ground finished.

Wheels:

Tyre & running tread: Made of phenolic resin, very high static load capacity, smooth running performance on even floors. Tread colour: black

Rim / wheel centre: -

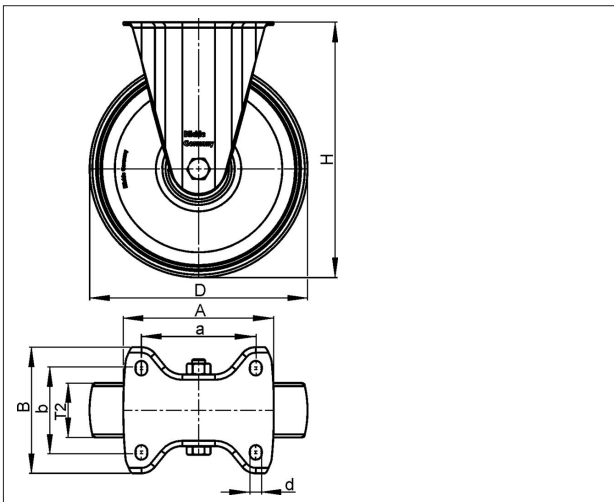

Technical data

Wheel Ø (D)	150 mm
Wheel width (T2)	50 mm
Load capacity	300 kg
Total height (H)	190 mm
Unit weight	2.133 kg
Temperature range from	-35 °C
Temperature range to	300 °C
Tread & tyre hardness	90° Shore D
Bearing type	
Plate size (A,B)	140 x 110 mm
Bolt hole Ø (d)	11 mm
Bolt hole spacing (a,b)	105 x 75-80 mm

Rolling resistance



Operating noise



Floor surface preservation

