

EA986LJ-80



EAN: 4047526610074

ID: 610071

Heat-resistant pressed stainless steel fixed castor with top plate fitting, Heat-resistant Blickle TempLine® Classic thermoset wheel


Bracket:

Made of pressed high-quality, chromium-nickel stainless steel (Material No. 1.4301/AISI 304). All parts incl. axle material are corrosion-resistant. Bolted wheel axle. Vibration-ground finished.

Wheels:

Tyre & running tread: Made of phenolic resin, very high static load capacity, smooth running performance on even floors. Tread colour: black

Rim / wheel centre: -

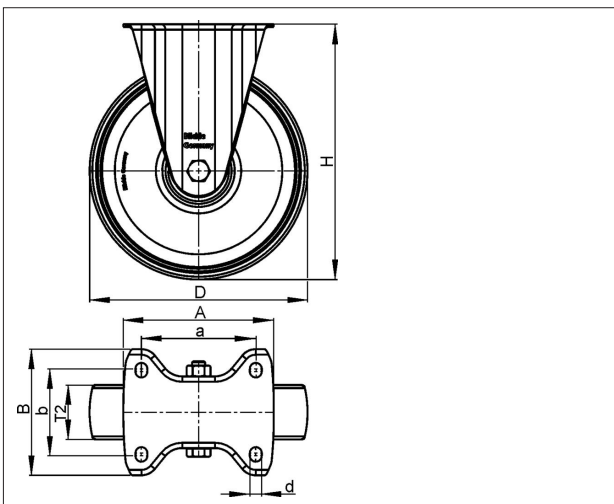

Technical data

Wheel Ø (D)	80 mm
Wheel width (T2)	32 mm
Load capacity	100 kg
Total height (H)	102 mm
Unit weight	0.386 kg
Temperature range from	-35 °C
Temperature range to	300 °C
Tread & tyre hardness	90° Shore D
Bearing type	
Plate size (A,B)	100 x 85 mm
Bolt hole Ø (d)	9 mm
Bolt hole spacing (a,b)	80 x 60 mm

Rolling resistance



Operating noise



Floor surface preservation



Blickle Räder+Rollen GmbH u. Co. KG

Heinrich-Blickle-Straße 1 · 72348 Rosenfeld · Germany
Telefon: +49 7428 932-0 · Telefax: +49 7428 932-209
E-Mail: info@blickle.com · Internet: www.blickle.com

© Blickle Räder+Rollen GmbH u. Co. KG 2013
Rosenfeld · Germany