

EA986LM-2



EAN: 4047526326159


ID: 326157

Nylon wheel

Tyre & running tread: Made of high-quality, impact-resistant nylon. Tread colour: natural white

Rim / wheel centre: -

Variants:
mit Feststeller "stop-fix"

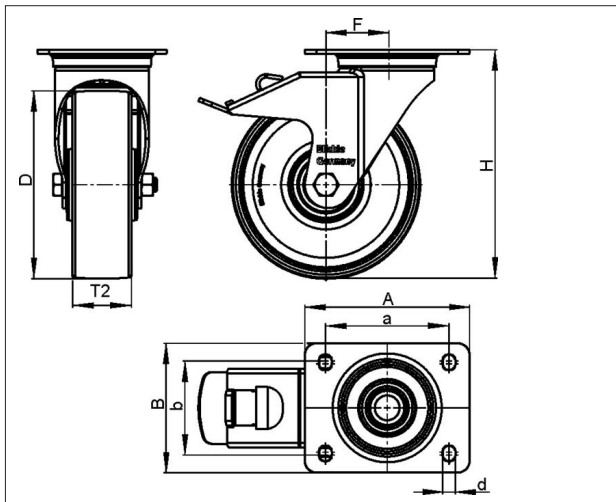

Technical data

Wheel Ø (D)	125 mm
Wheel width (T2)	40 mm
Load capacity	150 kg
Total height (H)	150 mm
Offset swvl castor (F)	40 mm
Unit weight	0.82 kg
Temperature range from	-25 °C
Temperature range to	80 °C
Tread & tyre hardness	70° Shore D
Bearing type	
Plate size (A,B)	100 x 85 mm
Bolt hole Ø (d)	9 mm
Bolt hole spacing (a,b)	80 x 60 mm

Rolling resistance



Operating noise



Floor surface preservation

