

EA986M- 180




EAN: 4047526263478

ID: 263475

Heavy duty wheel with elastic solid rubber tyres 'Blickle EasyRoll', with aluminium wheel centre

Tyre & running tread: Made of high-quality elastic solid rubber, in smooth rolling quality "Blickle EasyRoll", very high operational comfort, low-noise operation, low rolling resistance, very good floor preservation, vulcanised on the wheel centre. Tread colour: black

Rim / wheel centre: Made of die-cast aluminium. Vulcanised tyre.

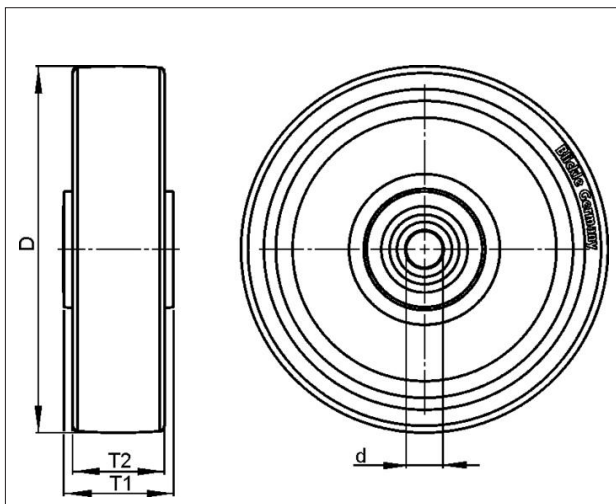

Technical data

Wheel Ø (D)	180 mm
Wheel width (T2)	50 mm
Load capacity	450 kg
Axle bore Ø (d)	20 mm
Hub length (T1)	60 mm
Unit weight	1.362 kg
Temperature range from	-25 °C
Temperature range to	80 °C
Tread & tyre hardness	65° Shore A
Bearing type	

Rolling resistance



Operating noise



Floor surface preservation



ALEV 180/20K

Variants



With non-marking grey
tyre