

EA986MA- 58




EAN: 4047526004873

ID: 4879

Nylon wheel

Tyre & running tread: Made of high-quality, impact-resistant nylon, very low rolling and swivelling resistance, smooth running performance on even floors, very high abrasion resistance. Tread colour: black

Rim / wheel centre: -

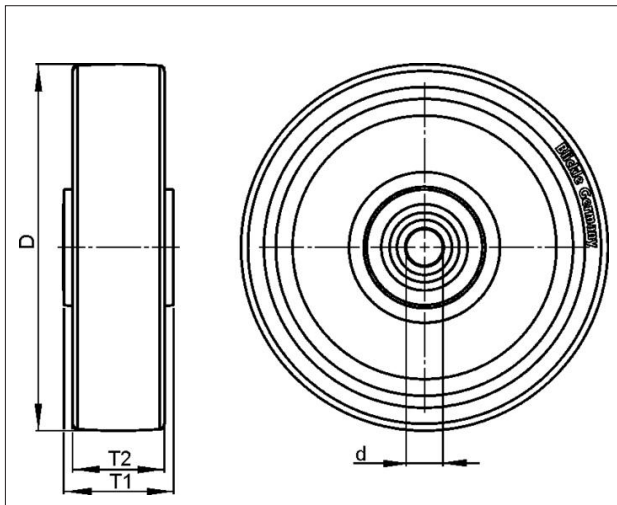

Technical data

Wheel Ø (D)	58 mm
Wheel width (T2)	29 mm
Load capacity	100 kg
Axle bore Ø (d)	10 mm
Hub length (T1)	31 mm
Unit weight	0.042 kg
Temperature range from	-25 °C
Temperature range to	80 °C
Tread & tyre hardness	70° Shore D
Bearing type	

Rolling resistance



Operating noise



Floor surface preservation

