

EA986MA- 75




EAN: 4047526105419

ID: 105411

Nylon wheel

Tyre & running tread: Made of high-quality, impact-resistant nylon, very low rolling and swivelling resistance, smooth running performance on even floors, very high abrasion resistance. Tread colour: black
Rim / wheel centre: -

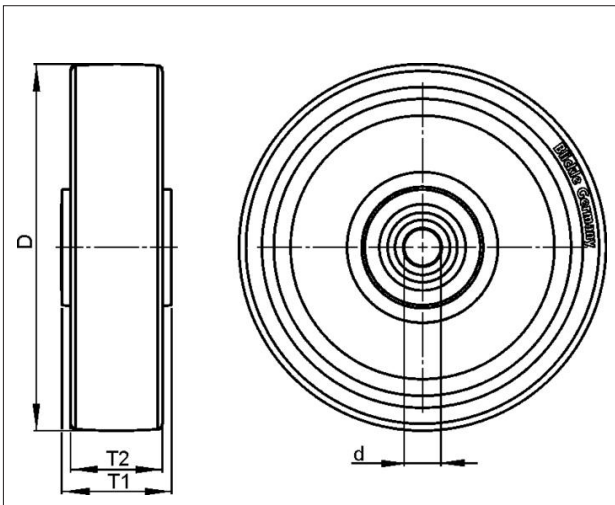

Technical data

Wheel Ø (D)	75 mm
Wheel width (T2)	23 mm
Load capacity	100 kg
Axle bore Ø (d)	8 mm
Hub length (T1)	29.5 mm
Unit weight	0.046 kg
Temperature range from	-25 °C
Temperature range to	80 °C
Tread & tyre hardness	70° Shore D
Bearing type	

Rolling resistance



Operating noise



Floor surface preservation

