

EA986MA- 80




EAN: 4047526574895

ID: 574897

Nylon wheel

Tyre & running tread: Made of high-quality, impact-resistant nylon, very low rolling and swivelling resistance, smooth running performance on even floors, very high abrasion resistance. Tread colour: black

Rim / wheel centre: -

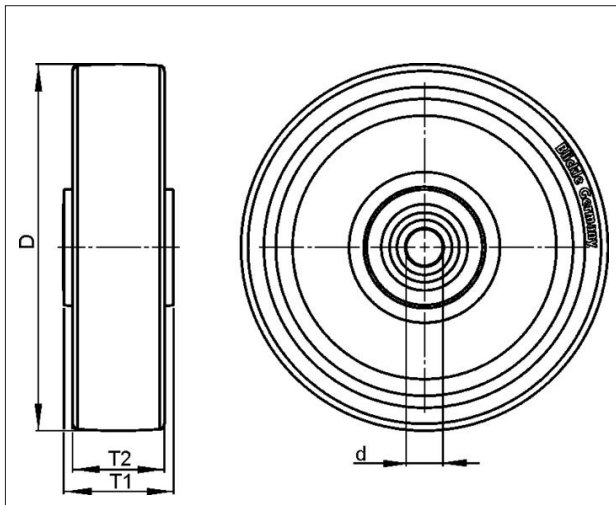

Technical data

Wheel Ø (D)	80 mm
Wheel width (T2)	32 mm
Load capacity	220 kg
Axle bore Ø (d)	12 mm
Hub length (T1)	35 mm
Unit weight	0.087 kg
Temperature range from	-25 °C
Temperature range to	80 °C
Tread & tyre hardness	70° Shore D
Bearing type	

Rolling resistance



Operating noise



Floor surface preservation

